





Product No. DOSIN-801-0240				
REV	DESCRIPTION	DMN	DATE	APPROVEN
A	First issue	JIM	2012/11/02	John Kine

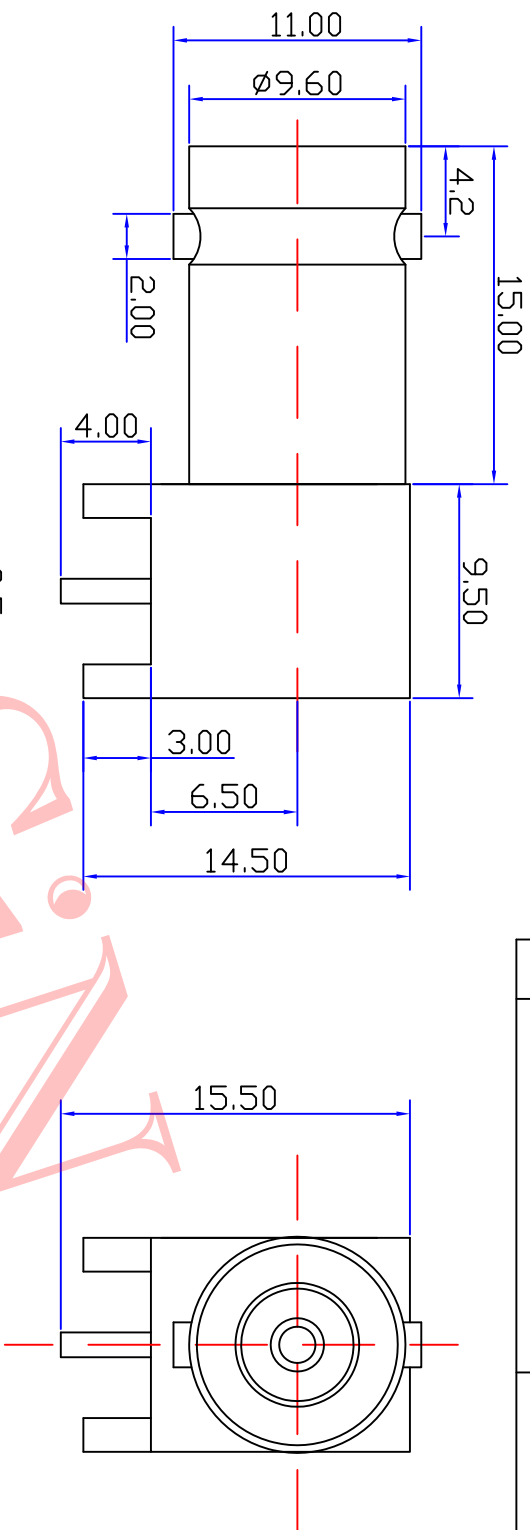

Specifications

Impedance: 75 Ohms
Frequency Range: DC~3G
VSWR: 1.3MAX
Working Voltage: 500V rms @ sea level
Insulation Resistance: 5000 Ohms min
Temperature Range: -55°C TO +155°C
Relative Temperature: $\leq 95\%$ (40° C $\pm 2^\circ$ C)
Drawings products are in line with ROHS standards

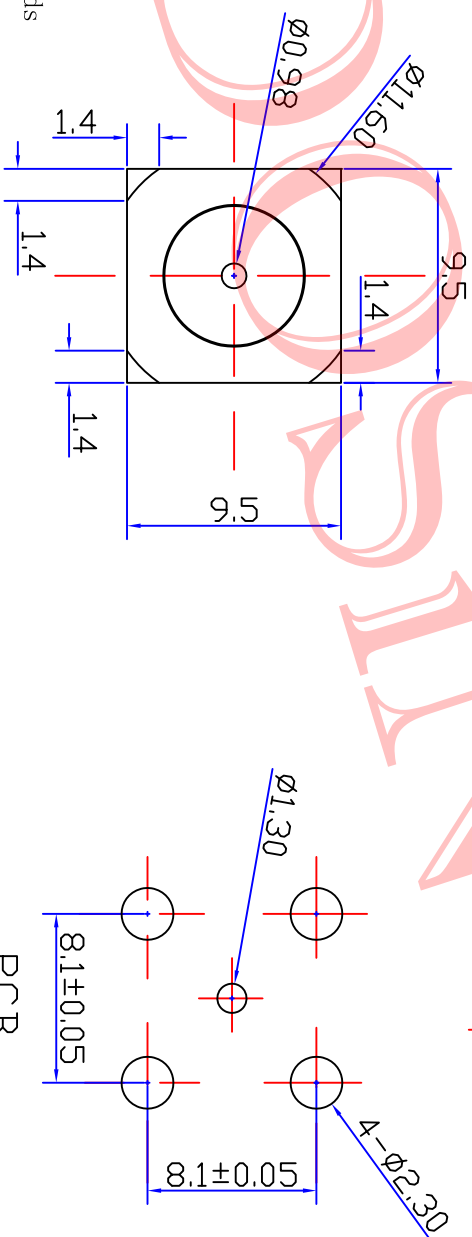

NOTE:									
DRAWN		2012/11/10		Tolerance		0-6 6-30 30-120 Angular ±0.20 ±0.30 ±0.5 ±2°			
Zel in. Zhang		View							
CHECKED		UNIT		MM					
APPROVALS		SCALE		1:1					
John Kine		12/04.2012							
A		B		C		D		E	
F									
G									

6									
C									
INSULATOR									
TEFLON									
NONE									
1									
B									
CONTACT PLATING									
BRASS									
GOLD									
1									
A									
BODY									
BRASS									
NICKEL									
1									
ND									
DESCRIPTION									
MATERIAL									
FINISHED									
QTY									
A									
B									
C									
D									
E									
F									
G									

Dosin Industrial(H.K.)Co.Ltd									
E-mail:dosin2005@163.com									
dosin2005@dosin-china.com									
W eb:http://www.dosinconn.com									
TEL:(0086)769-81153906									
FAX:(0086)769-81875836									
Dosin Hardware Electronics Co.,Ltd									

Name:		BNC CONNECTOR		DNN	
SIZE		Product NO.		REV	
A		DOSIN-801-0240		B	
Date/Time		CAD FILE		SHEET: 1 OF 1	
2012/11/02		D/company drawings/BD			