




Product NO.



RHT-634-1300

ISSUE	DESCRIPTION	DWN	DATE	APPROVEN
RI.0	First issue	Gavin	2019/12/17	JIM.KING

 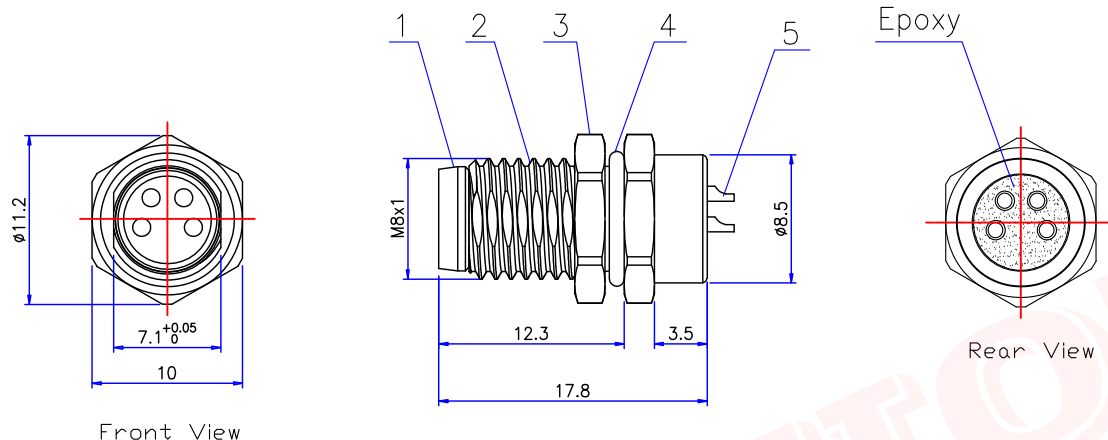


NOTES:

 
- Rated voltage/current: 3pin: 60V/3A
4pin: 60V/3A
5pin: 60V/3A
6, 8pin: 30V/1A
- Withstanding voltage: 3, 4pin: AC850V/1 Min
5, 6, 8pin: AC650V/1 Min
- Levels of protection: IP67
- Connection mode: Soldering
- Operating temperature: $-20^{\circ}\text{C} \sim +85^{\circ}\text{C}$
- RoHS Compliance

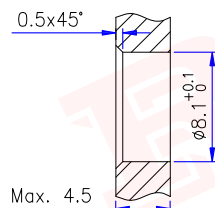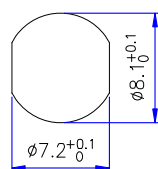Recommended
Mounting Hole

Pin height




2~5P

 


6P, 8P

Pin Assignments Front View

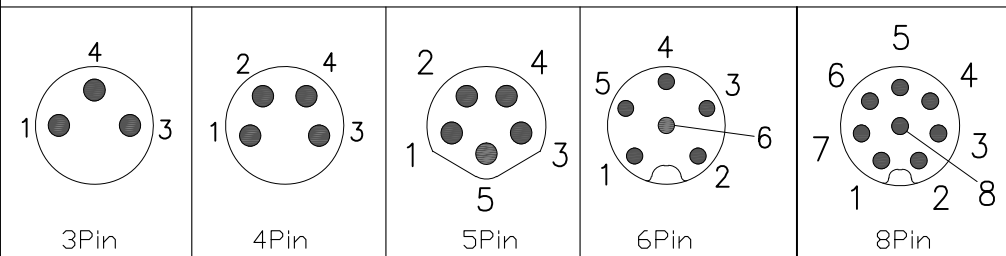

5	Contacts	Brass	Gold	3-8
4	O-Ring	Rubber		1
3	Nut M8*1	Brass	Nickel	1
2	Body	Brass	Nickel	1
1	Insulator	PA66	Black	1
NO	Description	Material	Finish	Qty

-TOLERANCES-
UNLESS OTHERWISE
SPECIFIEDUNLESS OTHERWISE SPECIFIED
TOLERANCES FOR MILLIMETERS ARE:
0.5 - 8mm $\pm 0.20\text{mm}$
8 - 30mm $\pm 0.25\text{mm}$
30 - 120mm $\pm 0.30\text{mm}$ dosinconn DOSIN INDUSTRIAL(HK)CO.,LTD
Web: http://www.dosinconn.com
江门市德索连接器有限公司
Dosing2005@dosin-china.com
Jiangmen Dosin Connector Co., LTD
Tel: (0086)769-81153906
Fax: (0086)769-81875836PART DESCRIPTION:
Circular Panel Mount, Male, M8

Appr: JIM.KING

P/N: RHT-634-1300

Check:

Date Scale Unit Type Page

Draw:

2019.12.17 Free MM Z 1/1