

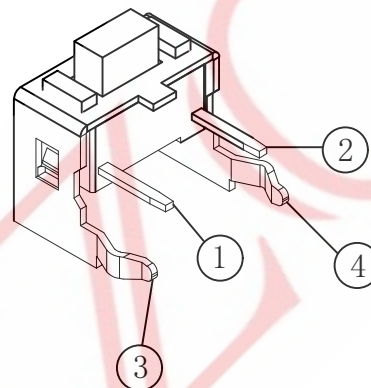
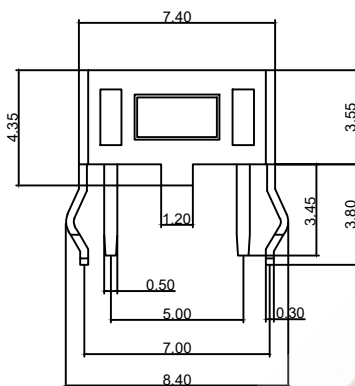


电路图

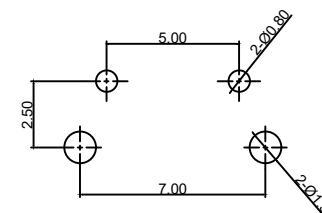

PCB. 焊接图

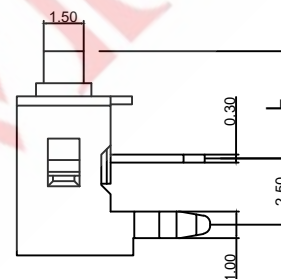

- A. 系列:T-3*6mm侧按支架
B. 贴装方式:2-卧插
C. 引脚规格:K-2PIN
D. 操作高度:43-4.3/45-4.5/50-5.0mm
E. 操作力度:1-180/2-260gf
F. 操作寿命:1-20,000次
G. 固定方式:1-支架
H. 物料编码:0-常规


主要技术参数、性能

The Main Thchnology Performance

额定电流、电压 Rate voltage,current	50mA DC12V
接触电阻 Contact resistance	$\leq 100\Omega$
按力 Operating force	$\pm 50\text{gf}$
行程 Travel	$0.20 \pm 0.10\text{mm}$
绝缘电阻 Insulated resistance	$\geq 100\Omega$
介电强度 Dielectric strength	$\geq 250\text{VAC}/1\text{min}$

			GENERAL TOLERANCE	
			$\geq 0 \sim 2 <$	± 0.15
DESIGN	WANGGUIFA	2018.06.12	$\geq 2 \sim 5 <$	± 0.25
CHECKED	ZHENGUILAN	2018.06.12	$\geq 0 \sim 2 <$	± 0.15
APPROVED	LILIANJIANG	2018.06.14	≥ 5	± 0.35

 FIRST VIEW



The copyright belongs to samzo parts [China] Co., Ltd. please use the material after samzo parts agree to authorize. The final right of interpretation belongs to samzo parts.
WWW.KKK-JP.COM

TITLE:	
--------	--

3*6*H 側按支架

of DWG NO: T2K00-P0031

PART NO: T2K004310

MODEL NO: T2K-**-**-10

NAME:

TACT SWITCH

SAMZO COMPONENTS
Electronic switch and connector manufacturer