



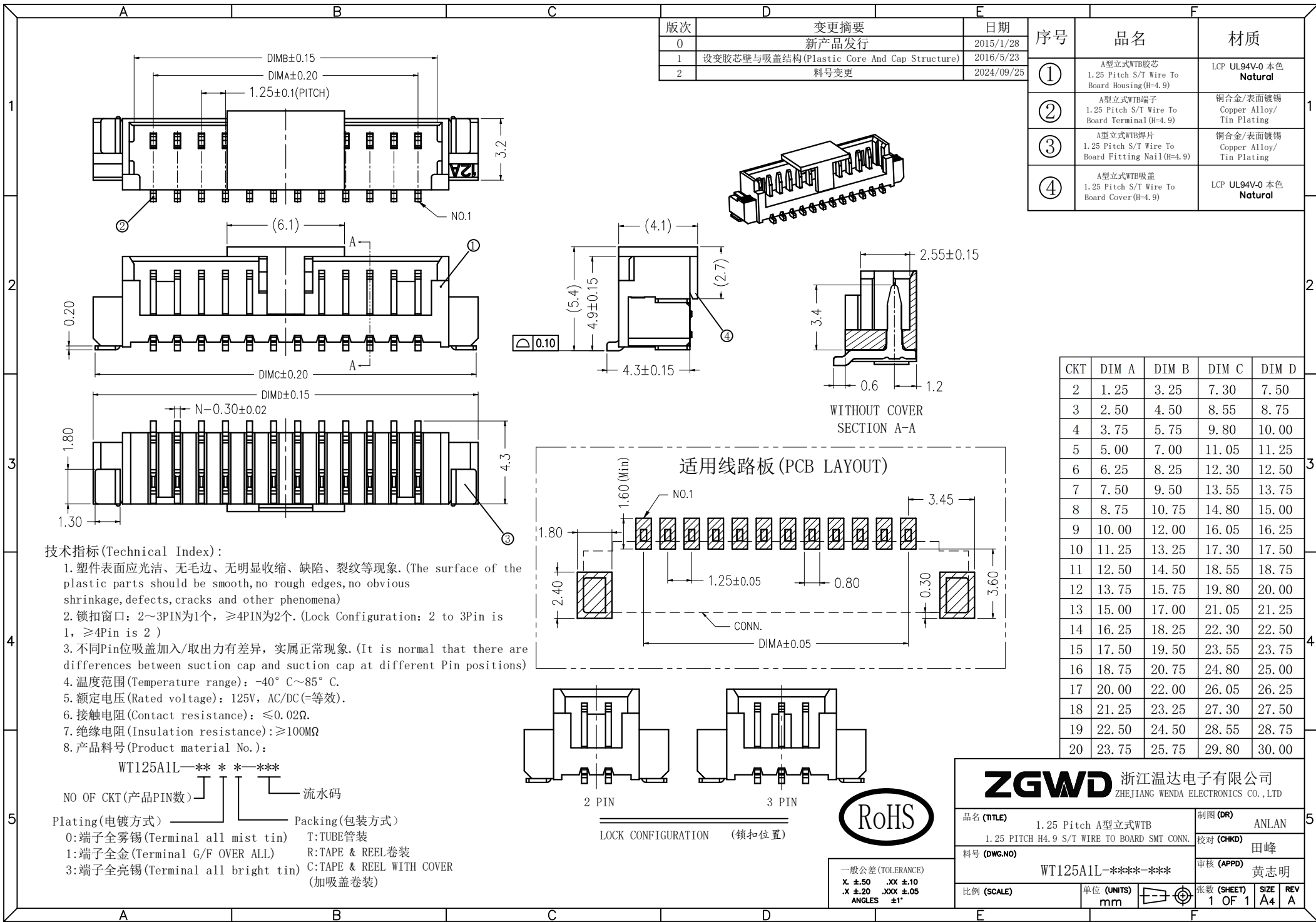

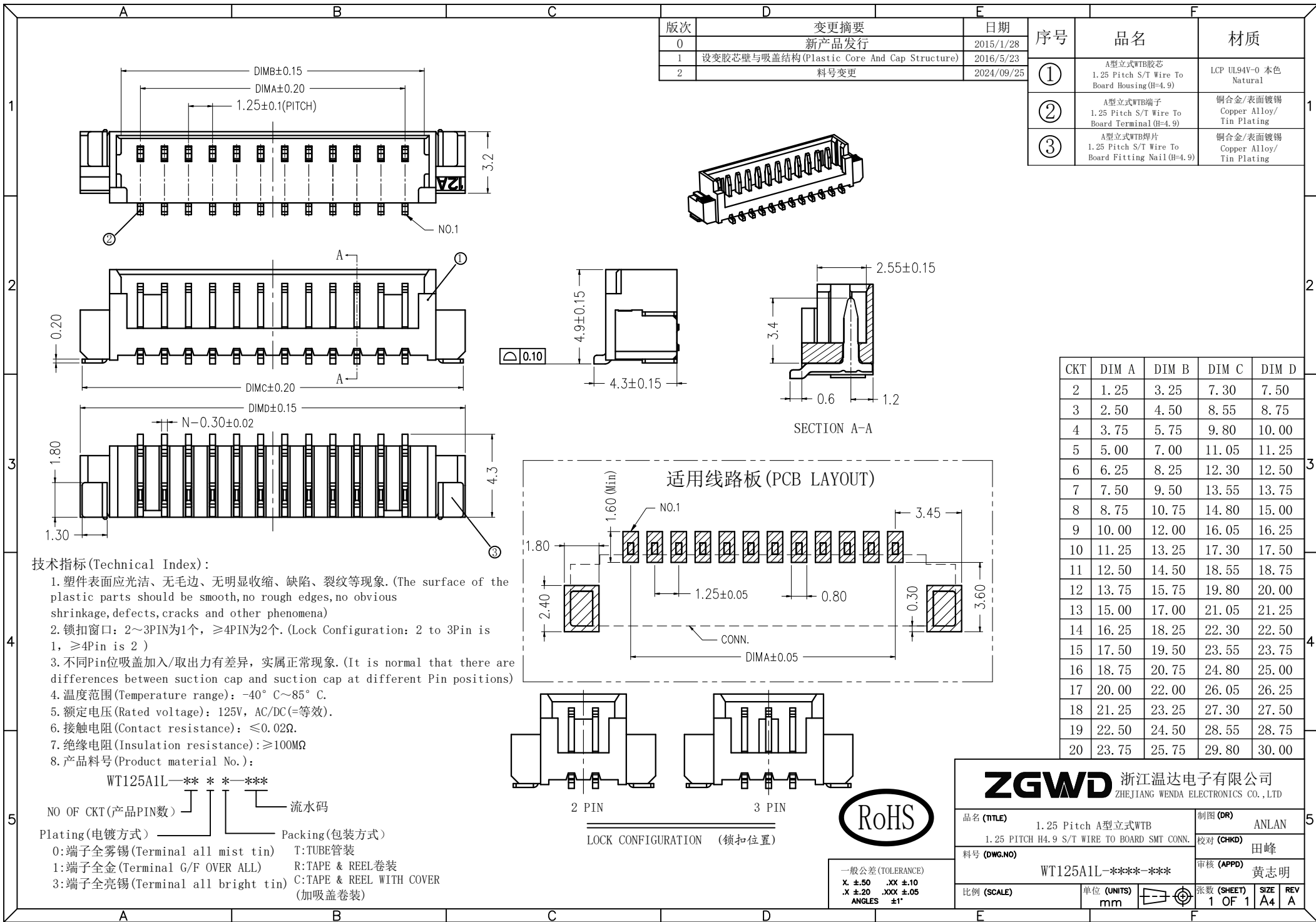

技术指标 (Technical Index):

- 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。(The surface of the plastic parts should be smooth, no rough edges, no obvious shrinkage, defects, cracks and other phenomena)
- 锁扣窗口: 2~3PIN为1个, ≥4PIN为2个。(Lock Configuration: 2 to 3Pin is 1, ≥4Pin is 2)
- 不同Pin位吸盖加入/取出力有差异, 实属正常现象。(It is normal that there are differences between suction cap and suction cap at different Pin positions)
- 温度范围 (Temperature range): -40° C~85° C.
- 额定电压 (Rated voltage): 125V, AC/DC (=等效).
- 接触电阻 (Contact resistance): ≤0.02Ω.
- 绝缘电阻 (Insulation resistance): ≥100MΩ
- 产品料号 (Product material No.):

WT125A1L-***-***-***

NO OF CKT (产品PIN数) 流水码

Plating (电镀方式) Packing (包装方式)

0: 端子全雾锡 (Terminal all mist tin) T: TUBE管装

1: 端子全金 (Terminal G/F OVER ALL) R: TAPE & REEL卷装

3: 端子全亮锡 (Terminal all bright tin) C: TAPE & REEL WITH COVER (加吸盖卷装)