


	UL	IEC
1.Rated Voltage :	300V	250V
2.Rated Current :	8A	7A
3.Torque Value :	M2, 1.77Lb.in	M2, 0.2N.m
4.Wire Range:	28-16AWG	0.5-1.5mm ²
5.Stripping Length :	6-7mm	
6.Withstanding Voltage :	AC1600V/1Min.	
7.Operating Temperature :	-40°C~+105°C	
8.RoHS Compliance		
9.Safety Approval :	c  	
10."★" is the key quality control point		

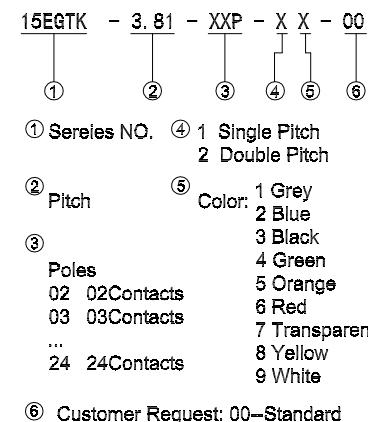

Total Pitch Tolerances in mm								Nominal dimension range in mm										$\perp$		$\equiv$	$-$	$//$	
over 0	over 30	over 53	over 70	over 90	over 115	over 150	over 250	over 350	over 0	over 30	over 53	over 70	over 90	over 115	over 150	over 200	over 250	over 0	over 10	all	over 0	over 100	over 150
to 30	to 53	to 70	to 90	to 115	to 150	to 250	to 350	to 500	to 30	to 53	to 70	to 90	to 115	to 150	to 200	to 250	to 320	to 10			to 100	to 150	to 150
± 0.18	± 0.20	± 0.25	± 0.3	± 0.35	± 0.44	± 0.60	± 0.70	± 0.85	± 0.20	± 0.25	± 0.30	± 0.35	± 0.44	± 0.55	± 0.70	± 0.80	± 0.90	0.2	0.3	0.3	0.2	0.3	0.5

				OPERATION		SCALE		Fit		东莞市宇熙精密连接器有限公司 www.yxcon.com Dongguan Yuxi Electronic Co.,Ltd.		
				X.X	±0.25	UNIT		MM				
				X.XX	±0.20	SIZE	A4	DESIGN	赵文品2024.10.10	PART NO.	15EGTK-3.81-XXP-XX-00	
				X.XXX	±0.10							
				Angle	±3°	SHEET	1/1	CHECK		TITLE:		
REV	DATE	SYMBOL		MODIFICATION DESCRIPTION		DIM	TOL	PROJ.		APPROVE		Customer No.