

Ordering Information
P220-32 05 A0 B U 225 A 1

1. 材料 (MATERIAL)

Housing:PA6T+30%G. F UL94V-0, Color:Black

Contact: Brass, GOLD PLATING OVER ALL

30u" MIN NICKEL UNDERPLATING OVER ALL

2. 特性 (characteristics):

额定电流: 2 AMP

Raring Current:2 AMP.

接触阻抗: 20 mΩ MAX.

Contact Resistance: 20 mΩ MAX.

绝缘阻抗: 1000 MΩ MIN.





Insulating Resistance:1000 MΩ MIN.

耐电压: AC 500V/分钟.

Withstanding Voltage:AC 500V/Minute.

温度范围: -40°C to $+105^{\circ}\text{C}$

Temperature Range: -40°C to $+105^{\circ}\text{C}$

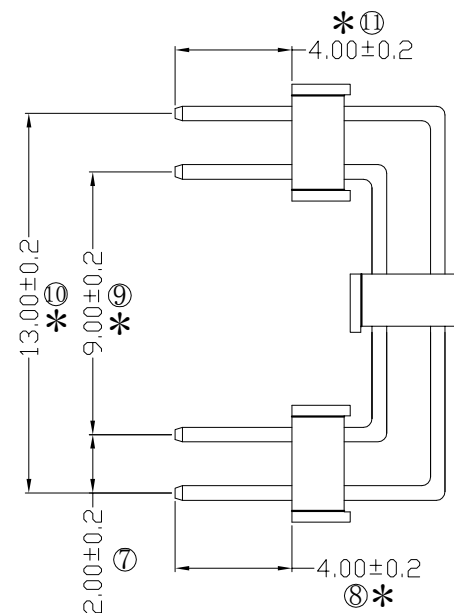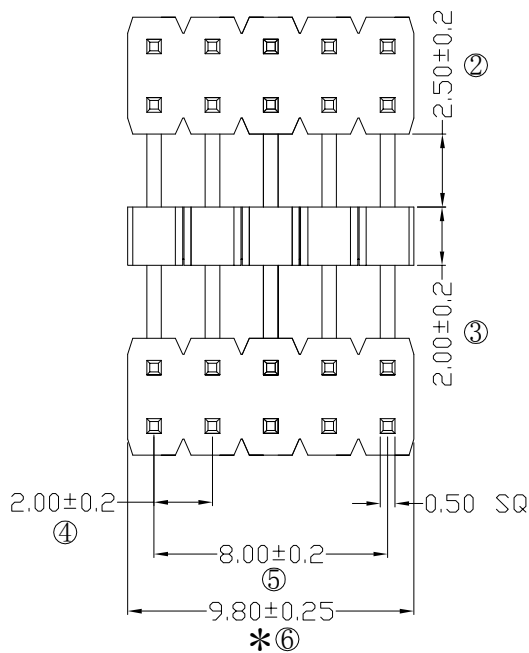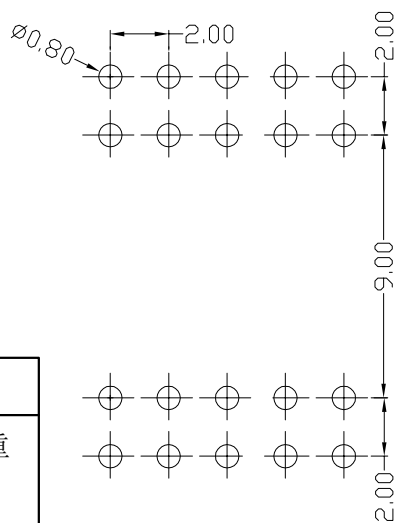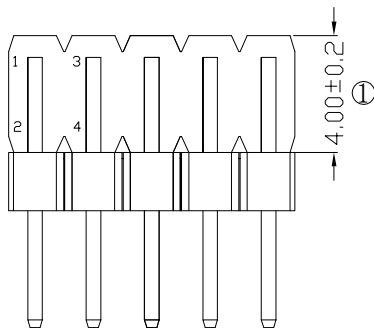

RoHS
COMPLIANT

客编：

注意事项

1. 带*为品质重点检验尺寸

				OPERATION		SCALE		Fit		 东莞市宇熙精密连接器有限公司 Dongguan Yuxi Electronic Co., Ltd.			
				X.X	±0.25	UNIT		MM		www.yxcon.com			
				X.XX	±0.20	SIZE		A4		DESIGN		张伟 2020.12.17	
				X.XXX	±0.10								
A0	2020.12.17	/	新版发行	Angle		±3°		SHEET		1/1		CHECK	
REV	DATE	SYMBOL	MODIFICATION DESCRIPTION	DIM		TOL		PROJ.				APPROVE	
												PART NO. P220-3205A0BU225A1 TITILE: 2.0排针 2*5P*3 L=22.5/4.0(3.25)/4.0(3.25)/30.5 桥型 短针 脚距9.0 DIP:4.0 PA6T料 镀普金 100PCS/袋+盒装	
												Customer No.	