

Operation: DIP/3.5&卧式 5PIN 音频插座



LTEM NO.:PJ-328A-P5

(L14.0×W6.5×H5.0mm 3.5-PHONE-JACK)



Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	50mA, 24V DC	
	Initial Contact Resistance	30mΩ max.	50mΩ max.
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
	There No Load	6,000 Cycles	5,000 Cycles
Durable Performance	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-25℃~+75℃(Operating Temp:)	

卧式插装 DIP


側向導入 LATERAL

精密部品 NICETY


可靠 STABILIZE

適合環保 RoHS

Unit:mm

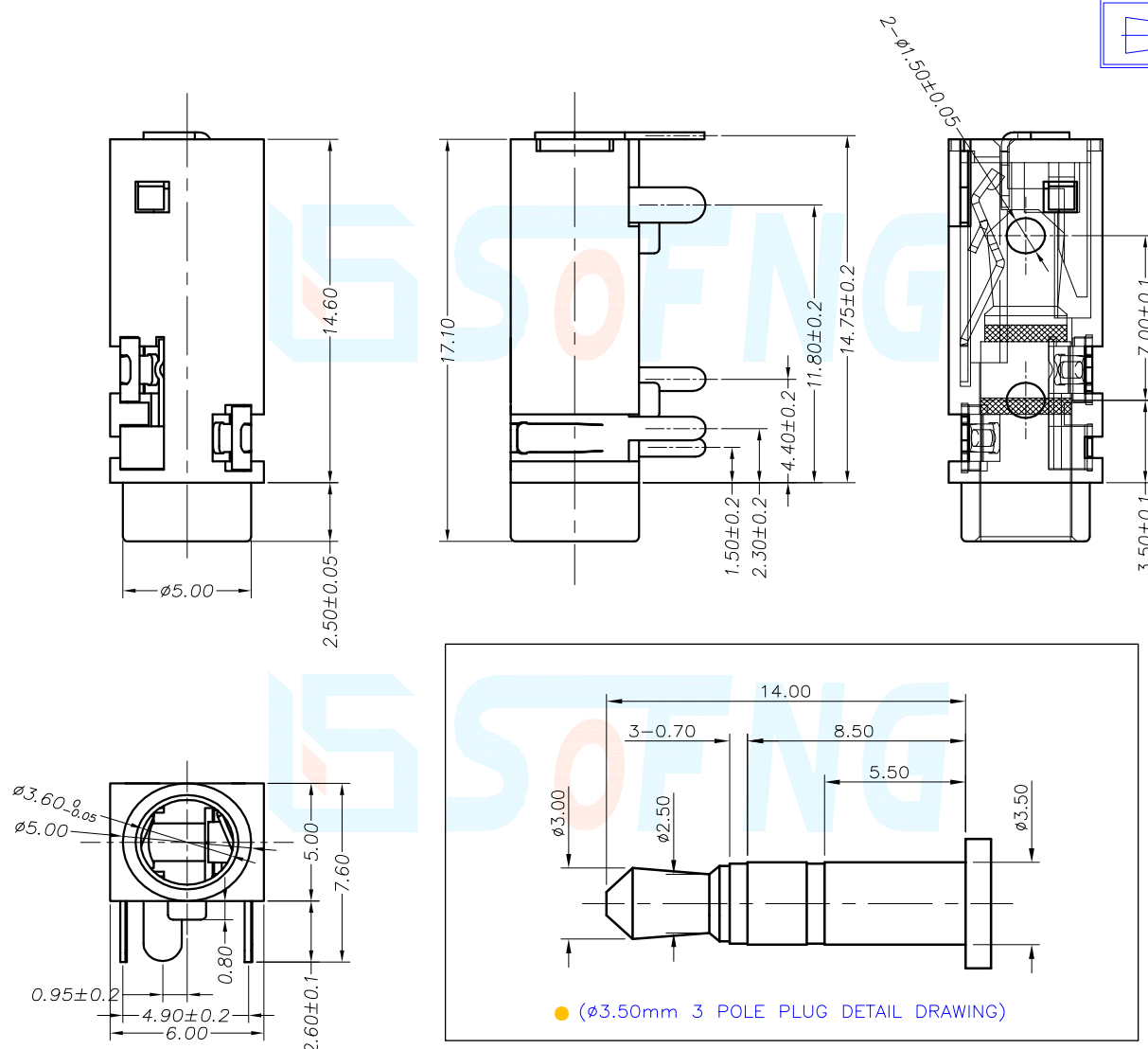

Operating Force	Inward	5.0~8.0N. (1N.=100gram-force)	Solder-ability (Max.)	Manual: 350℃, 3sec.
	Exiting	5.0~8.0N. (1N.=100gram-force)		

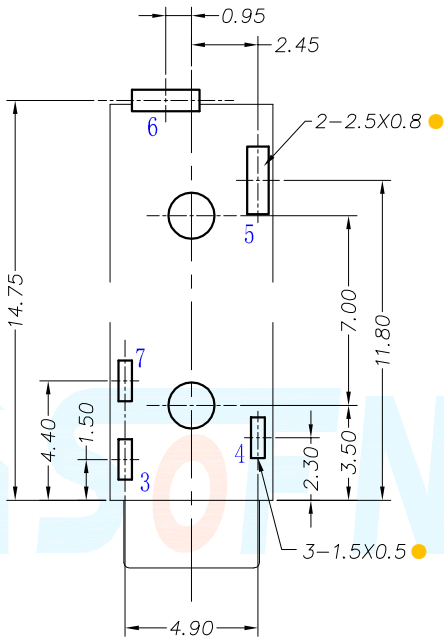

DECIMALS	ANGLES
.X :±0.20	X.° :±1.5°
.XX :±0.10	X.X° :±1.0°
.XXX :±0.05	.XXX° :±0.5°

Pin Definition



Material declaration

No.	NAME	Type	Description
①	基座	1	PPA/PBT (Black)耐热塑胶
②	后盖	1	PPA/PBT (Black)耐热塑胶
③	接觸端子#1	1	C5191R-H (t=0.20mm)磷铜[镍基镀银]
④	接觸端子#2	2	BE-CU (t=0.25mm)铍青铜铜[镍基镀银]
⑤	接觸端子#3	1	C5191R-H (t=0.30mm)磷铜[银基镀镍]
⑥	接觸端子#4	1	C5191R-H (t=0.30mm)磷铜[镍基镀银]



PJ-328A-P5	PJ-328A-A4	PJ-328A-B4	PJ-328A-A3	PJ-328A-B3

本品不屬於危害性廢棄物,須丟棄時可以委託
回收商予以回收再生處理。
Products do not belong to

注記 NOTICE

1. 碩方公司擁有最終解釋權; The company reserves the right of final interpretation;
2. 文件禁止外洩、轉載; Leaked and reproduced prohibited;
3. 未經授權修改無效。Modify is invalid.

運送時本產品不要直接與水、酸鹼性化學物質
接觸,或放置於含有以上氣體環境中,並且需要
注意會有滑落、側翻的危險發生; 運輸過程中
不能有碰撞或者擠壓,須保證溫度與濕度適中
[常溫 25℃,濕度在 50℃以內],不可導致材料變
形或氧化。