



YX-A28-R943052-G0812



APPLICATIONS

- Cross outlet
- Coil attached square diskette, size: 96*52mm*1.0mm (Adhesive backing)
- Double-sided magnetic tape
- Attach the coil to double-sided tape
- Double line tinning

SHAPE & DIMENSIONS

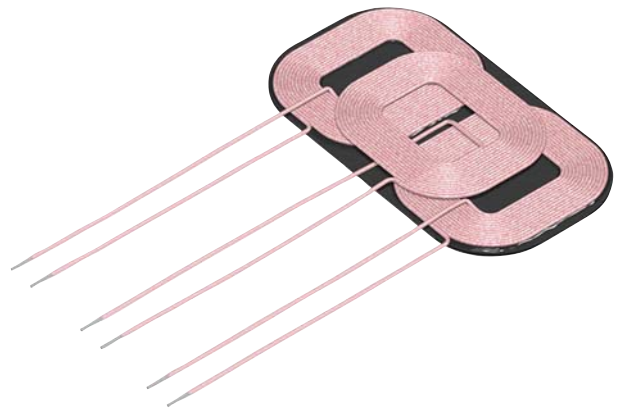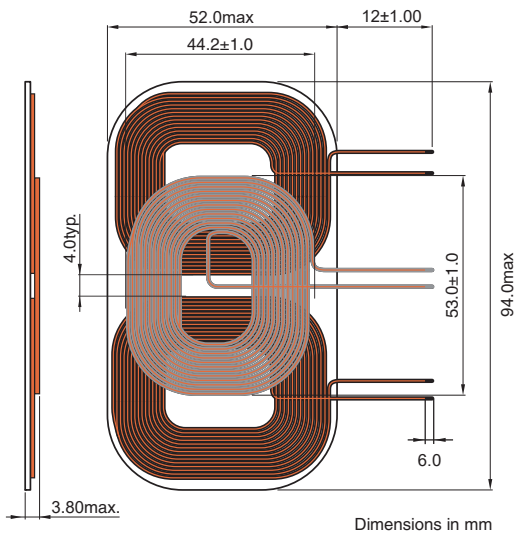

AIR COIL SPECIFICATIONS

Number of Coils	Wire Diameters	Turns Ratio
3	ø0.08mm x 105P	9T

MAXIMUM RATINGS

Operating Temperature / Humidity	Storage Temperature / Humidity
-40 to +85°C / 10 to 65% R.H.	-25 to +125°C / 10 to 65%

ELECTRICAL CHARACTERISTICS

OCL [100kHz 0.1V] (μH)	DCR [100kHz 0.1V] (mΩ)	WPC Compliant
6.30 ± 5%	34.00	Yes

PACKAGING : BOX TYPE

Dimensions (mm)		Quantity (pcs)	
Tray	3	Qty per tray	80
Small carton	320x320x55	Qty per small carton	3
Outer carton	350x350x180	Qty per outer carton	240

OTHERS

Weight (g) typ.	38.50
--------------------	-------