



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Size

2B

Series

B - Indoor keyed

Technical details



Form & Material

Shell style / Model id	BFG - Cap for plug
Housing material	POM (Polyoxymethylene) shell without treatment, silicone gasket
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	1.84 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Temperature range	-50°C / +100°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

Drawings

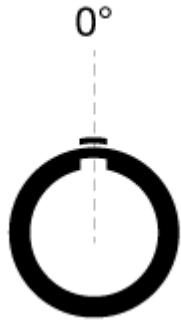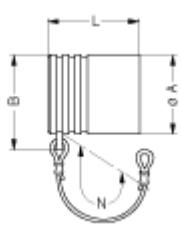

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/bfg-2b-100-pcsg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Dimensions

	A	B	L	N
mm.	15	18	15	85
in.	0.59	0.71	0.59	3.35

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/bfg-2b-100-pcsg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.