





Series 80 Mighty Mouse Backshells and Accessories

Jam Nuts 809-094

Jam nut for Mighty Mouse connectors

Replace lost or damaged jam nuts with these standard replacement parts. Jam nut fits all Series 80 jam nut receptacles. Use with Glenair tool 600-146

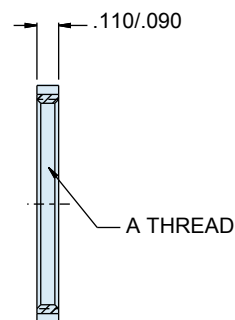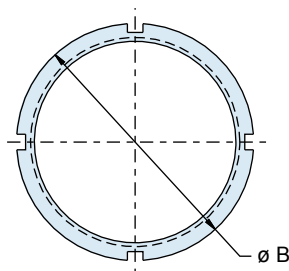

X

How To Order			
Sample Part Number	809-094	-M	7
Series (See Table I)	809-094		
Shell Material and Finish	C = Aluminum / Black Anodize (Non-Conductive) RoHS Compliant		
	M = Aluminum / Electroless Nickel		
	NF = Aluminum / Cadmium with Olive Drab		
	ZN = Aluminum / Zinc-Nickel with Olive Drab Chromate		
	Z1 = Stainless Steel / Passivated		
Dash No.	See Table I		

Dash No.	800	801	804		805	A Thread Class 2B	B Dia
			-00 style	-07 style			
1	5					.3125-28 UN-2B	0.43
2	6	5				.3750-28 UN-2B	0.50
3	7	6				.4375-28 UNEF-2B	0.56
3-3				5		.4375-32 UN-2B	0.56
4	8		5	6		.5000-32 UN-2B	0.62
5					8	.5625-28 UN-2B	0.68
5-5	9	7,8	6			.5625-32 UN-2B	0.68
6		9		7,8		.6250-28 UN-2B	0.75
6-6	10					.6250-32 UN-2B	0.75
7		10	7,8	9	9,10	.6875-28 UN-2B	0.81
8	12	11	9	10	11	.7500-28 UN-2B	0.87
9			10	11	12	.8125-28 UN-2B	0.93
10	14	13	11	12	13	.8750-28 UN-2B	1.00
11	15					.9375-28 UN-2B	1.06
12			12	14	15	1.0000-28 UN-2B	1.12
13		16	14	15		1.0625-20 UN-2B	1.18
14		17	15			1.1250-28 UN-2B	1.25
15					18	1.1875-28 UN-2B	1.31
16		19			19	1.2500-28 UN-2B	1.37
18		21			21	1.3750-28 UN-2B	1.50
20					23	1.5000-28 UN-2B	1.62

Dimensions in Inches (millimeters) are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[809-035Z123](#) [809-053-6-6](#) [809-083-06G3-04N](#) [809-084-07G7-SK](#) [809-094-M-5-5](#) [809-166-M6](#) [809-190-07](#) [809-231-5-5](#) [809-297](#) [809-301](#)