



660-023 and -024 • 660-049 and -050 MIL-DTL-38999 Series III Type Metal and Composite Protective Covers Plug and Receptacle

MIL-DTL-38999 Series III Type metal and composite protective covers

B

How To Order

Product
SeriesMaterial/Finish
(Table II)Lanyard
(Table III)Attachment Dash No.
(Table IV, V, VI, or VII)
omit for "SK" slip knot attachment

660

- 023

M

17

H

5


- 01

Cover Type


-023 = metal plug cover
-024 = metal receptacle cover
-049 = composite plug cover
-050 = composite receptacle cover

Shell Size
(Table I)Attachment Length
(Inches)

-023 and -049 Plug Cover MIL-DTL-38999/32 Type

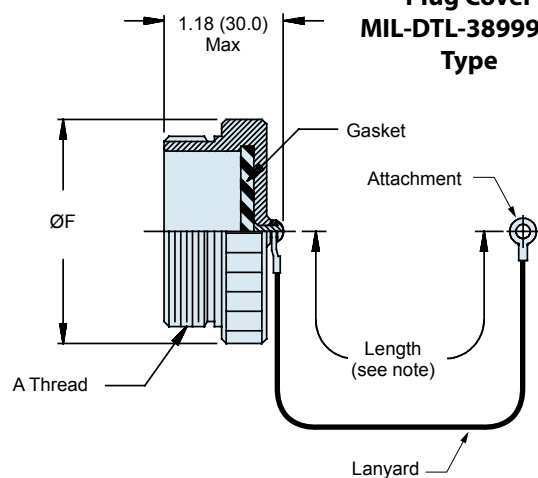

-024 and -050 Receptacle Cover MIL-DTL-38999/33 Type

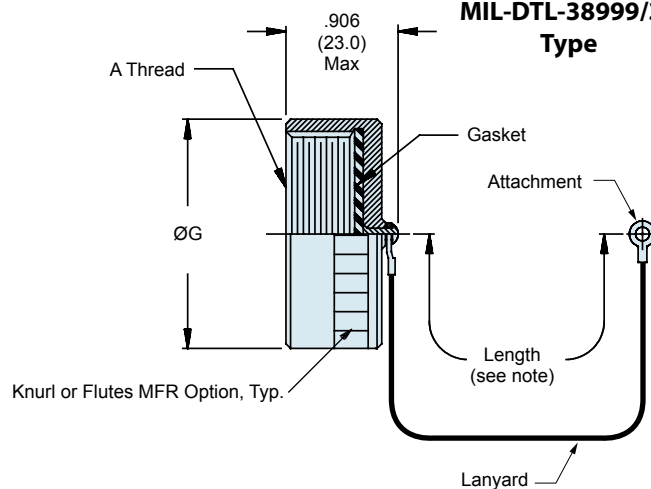

Material and Finish

Cover: See Table II • Gasket: Silicone • Hardware, Rivet: Stainless Steel/Passivate

Notes

Length tolerance for Sash Chain (S) is ± 1 link, for all other attachments $\pm .25$.

660-023 and -024 • 660-049 and -050
MIL-DTL-38999 Series III Type
Metal and Composite Protective Covers
Plug and Receptacle



MIL-DTL-38999
Series III Type

B

Available Lanyard Types (shown with optional eyelet attachment, see table III for lanyard style)

 
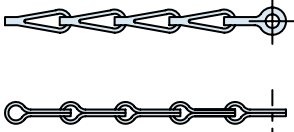
		
Bead Chain (Type D)	Sash Chain (Type S)	Rope (Types F, G, H, K, R, T, U)

Table I

Shell Size	A Thread	Ø F Max	Ø G Max
09	.6250 - 0.1P-0.3L-TS	0.906 (23.0)	.906 (23.0)
11	.7500 - 0.1P-0.3L-TS	1.024 (26.0)	1.102 (28.0)
13	.8750 - 0.1P-0.3L-TS	1.220 (31.0)	1.220 (31.0)
15	1.0000 - 0.1P-0.3L-TS	1.300 (33.0)	1.260 (32.0)
17	1.1875 - 0.1P-0.3L-TS	1.457 (37.0)	1.457 (37.0)
19	1.2500 - 0.1P-0.3L-TS	1.575 (40.0)	1.535 (39.0)
21	1.3750 - 0.1P-0.3L-TS	1.732 (44.0)	1.654 (42.0)
23	1.5000 - 0.1P-0.3L-TS	1.811 (46.0)	1.772 (45.0)
25	1.6250 - 0.1P-0.3L-TS	1.969 (50.0)	1.929 (49.0)

Table III: Lanyard Codes

Code	Description
D	Bead Chain, CRES, Passivated
F	Wire Rope, Nylon Jacket
G	Nylon Rope, Black
H	Wire Rope, Fluoropolymer Jacket
K	Nylon Rope, Olive Drab
N	No Lanyard
R	Wire Rope, PVC Jacket
S	#8 Sash Chain, CRES, Passivated
SK	Nylon Rope (Black) w/Slip Knot
T	Wire Rope, No Jacket
U	Wire Rope, Polyurethane Jacket

Table II: Material/Finish

Code	Material	Finish Description
C	Aluminum Alloy	Anodize, Black
G		Anodize, Hardcoat
M		Electroless Nickel
MT		Nickel-PTFE, Grey
NF		Cadmium, Olive Drab
ZN		Zinc-Nickel, Olive Drab
ZNU		Zinc-Nickel, Black
Z1	Stainless Steel	Passivate
ZL		Electrodeposited Nickel
XM	Composite	Electroless Nickel
XW		Cadmium, Olive Drab
XB		No Plating, Black

Refer to Appendix for material/finish details

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[660-024M25S9-02](#) [660-024M25S6-02](#) [660-023N25H4-01](#) [660-024Z111S5-05](#) [660-024M25S6-06](#) [660-023B23SK10](#)
[660-023B25SK10](#) [660-023M11D4-01](#) [660-050XO19N](#) [660-050XO23N](#) [660-024ZR13R5-09](#) [660-024ZR17F5-01](#)
[660-049XW11G6-04](#) [660-050XB11H3-01](#) [660-050XM25U5-05](#) [660-050XO11N](#) [660-024Z113F11-06](#) [660-024Z115S5-](#)
[01](#) [660-024Z119H5-110](#) [660-024Z125F4-02](#) [660-024Z1615N](#) [660-024Z1725H5-03-92](#) [660-024NF17U3-109-216](#)
[660-024NF21G8-04](#) [660-024NF23G3-112](#) [660-024NF23U8-06](#) [660-024NF25H10-05](#) [660-024Z111S5-01](#) [660-](#)
[024N21H4-06](#) [660-024NF11F5-107](#) [660-024NF11H5-56](#) [660-024NF13H6-01-59B](#) [660-024NF17F5-06](#) [660-](#)
[024NF17H3-109](#) [660-024M15S5-19-372](#) [660-024M17H4-01](#) [660-024M21G3-01](#) [660-024M21S9-02](#) [660-024M23S9-](#)
[02](#) [660-024N11S2.75-109-92](#) [660-024B25H4-01](#) [660-024C17H4-01](#) [660-024M11H6-01](#) [660-024M11S5-02](#) [660-](#)
[024M13S9-02](#) [660-024M15S4-108](#) [660-023ZR13F3-205](#) [660-023ZR19F3-108](#) [660-024B11H13-07](#) [660-024B11H5-01](#)
[660-024B13H5-02](#) [660-024B23F4-02](#) [660-023NF25H12-01](#) [660-023NF25S5-04](#) [660-023R21N](#) [660-023R23N](#) [660-](#)
[023Z117H5-17](#) [660-023Z125F10-02](#) [660-023M21H6-06](#) [660-023M21S9-02](#) [660-023MT11F5-104](#) [660-023N09R5-01](#)
[660-023N13H6-01](#) [660-023NF15H7-01](#) [660-023M11H5-103](#) [660-023M11S6-02](#) [660-023M13S9-02](#) [660-023M15S9-](#)
[02](#) [660-023M17S9-02](#) [660-023M19D4-01](#)