

HC-B24-HCLFD-PR-BK - Protective cover



1414633

<https://www.phoenixcontact.com/us/products/1414633>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Protective cover B24, for double locking latch, protective cover material: PA, height: 21.6 mm, seal: yes

Commercial data

| | |
|--------------------------------------|---------------------|
| Item number | 1414633 |
| Packing unit | 1 pc |
| Sales key | BF66 |
| Product key | BF7AZC |
| Catalog page | Page 654 (C-2-2019) |
| GTIN | 4055626030852 |
| Weight per piece (including packing) | 46.18 g |
| Weight per piece (excluding packing) | 20.44 g |
| Customs tariff number | 85389099 |
| Country of origin | DE |

HC-B24-HCLFD-PR-BK - Protective cover



1414633

<https://www.phoenixcontact.com/us/products/1414633>

Technical data

Notes

| | |
|---------|--|
| General | Protective cover for supporting base element with double locking latch |
|---------|--|

 
Product properties

| | |
|--------------|------------------|
| Product type | Protective cover |
| Housing type | Protective cover |
| Type | B24 |
| Seal present | yes |

Data management status

| | |
|------------------|----|
| Article revision | 00 |
|------------------|----|

Dimensions

| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 46 mm |
| Height | 21.6 mm |
| Length | 124 mm |
| Diameter | 30 mm |

Material specifications

| | |
|--|-----|
| Material Protective cover | PA |
| Flammability rating according to UL 94 | HB |
| Seal material | NBR |
| Material, protective cover | PA |

Mechanical properties

Mechanical data

| | |
|--------------|-----|
| Locking type | Pin |
|--------------|-----|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP66 |
| Ambient temperature (operation) | -20 °C ... 100 °C |

Mounting

| | |
|---------------|--|
| Assembly note | Plastic protective cover for short-term protection |
|---------------|--|

HC-B24-HCLFD-PR-BK - Protective cover




1414633

<https://www.phoenixcontact.com/us/products/1414633>

Drawings

Dimensional drawing

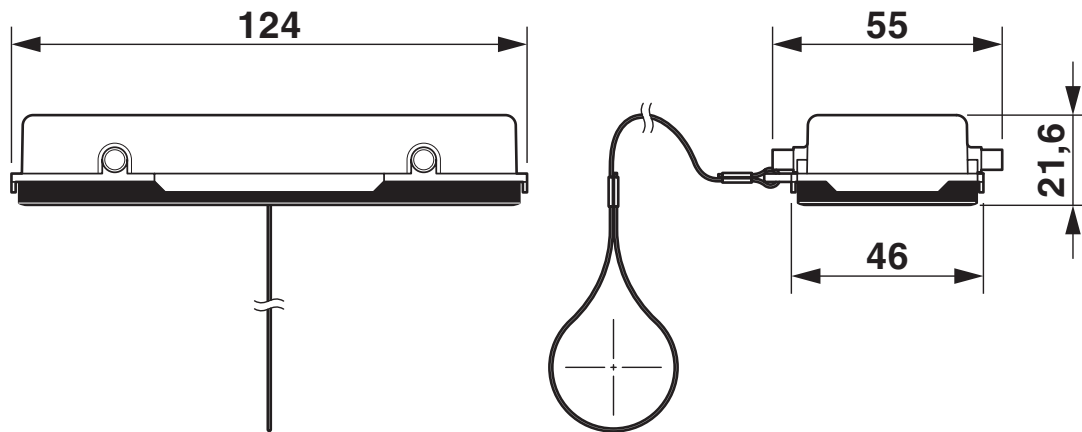

Dimensional drawing

HC-B24-HCLFD-PR-BK - Protective cover



1414633

<https://www.phoenixcontact.com/us/products/1414633>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-11.0 | 27440208 |
| ECLASS-13.0 | 27440208 |

ETIM

| | |
|----------|----------|
| ETIM 8.0 | EC002314 |
|----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

HC-B24-HCLFD-PR-BK - Protective cover



1414633
<https://www.phoenixcontact.com/us/products/1414633>

Environmental product compliance

| | |
|---|--|
| EU RoHS | |
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
| China RoHS | |
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |
| EU REACH SVHC | |
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com