


WRAPOST RECEPTACLES

FOR 0,38 - 0,64 DIAMETER PINS

0444

0444-X-17-XX-30-XX-02-0

Press-fit in 1,42 mounting hole

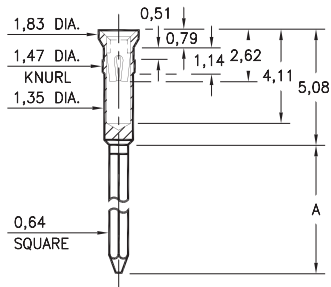


Basic Part Number	# of Wraps	Length A
0444-1	1	6,6
0444-2	2	9,4
0444-3	3	12,83

2601 ⇨ 2603

260X-0-17-XX-30-XX-02-0

Press-fit in 1,45 mounting hole

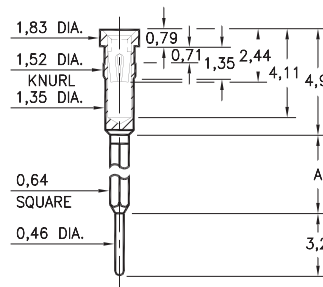


Basic Part Number	# of Wraps	Length A
2601-0	1	5,89
2602-0	2	8,89
2603-0	3	11,89

0445

0445-3-17-XX-30-XX-02-0


Press-fit in 1,42 mounting hole

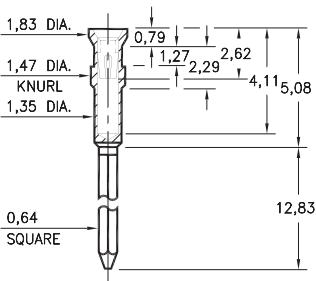

1047

1047-3-17-XX-30-XX-02-0

Press-fit in 1,42 mounting hole

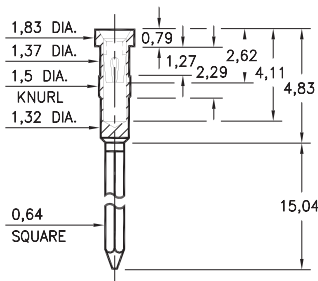

SPECIFICATIONS:

Shell Material: Brass Alloy 360, 1/2 Hard

Contact Material: Beryllium Copper Alloy 172, HT

Dimensions: Millimeters

Tolerances On: Lengths: ± 0,13

Diameters: ± 0,051

Angles: ± 2°



ORDER CODE: XXXX - X - 17 - XX - 30 - XX - 02 - 0

BASIC PART #

SPECIFY SHELL FINISH:

- 01 5,08µm TIN/LEAD OVER NICKEL
- ◆ 80 5,08µm TIN OVER NICKEL (RoHS)
- ◆ 15 0,25µm GOLD OVER NICKEL (RoHS)

SPECIFY CONTACT FINISH:

- 02 2,54µm TIN/LEAD OVER NICKEL
- ◆ 84 2,54µm TIN OVER NICKEL (RoHS)
- ◆ 27 0,76µm GOLD OVER NICKEL (RoHS)

SELECT CONTACT:

#30 or #32 CONTACT (DATA ON PAGE 253)

(For alternate contact choices, see groups B and C on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[2603-0-17-01-30-02-02-0](#) [2603-0-17-01-30-27-02-0](#) [2602-0-17-01-30-02-02-0](#) [2602-0-17-01-30-27-02-0](#) [1047-3-17-80-30-84-02-0](#) [0445-3-17-80-30-84-02-0](#) [0444-3-17-80-30-84-02-0](#) [0444-3-17-80-30-27-02-0](#) [0444-2-17-80-30-84-02-0](#) [0444-1-17-80-30-84-02-0](#) [0444-1-17-80-30-27-02-0](#) [1047-3-17-01-30-02-02-0](#) [1047-3-17-01-30-27-02-0](#) [0445-3-17-01-30-02-02-0](#) [0445-3-17-01-30-27-02-0](#) [0444-3-17-01-30-02-02-0](#) [0444-3-17-01-30-27-02-0](#) [0444-2-17-01-30-02-02-0](#) [0444-2-17-01-30-27-02-0](#) [0444-1-17-01-30-02-02-0](#) [0444-1-17-01-30-27-02-0](#) [2603-0-17-80-30-27-02-0](#) [2602-0-17-80-30-84-02-0](#) [2602-0-17-80-30-27-02-0](#) [2601-0-17-80-30-84-02-0](#) [2601-0-17-80-30-27-02-0](#) [0444-1-17-15-30-27-02-0](#) [0444-2-17-15-30-27-02-0](#) [0444-3-17-15-30-27-02-0](#) [0445-3-17-15-30-27-02-0](#) [1047-3-17-15-30-27-02-0](#) [2601-0-17-15-30-27-02-0](#) [2602-0-17-15-30-27-02-0](#) [2603-0-17-15-30-27-02-0](#)