



RUE SAINT-HENRI 11, P.O. BOX 834 - CH-2800 DELÉMONT / SWITZERLAND

Your selected product

Headers - Solder cup

Series 480

480-PP-2NN-00-001101

Double Row

2.54 mm, Solder cup

PCB header strips for wiring application with solder tail / connecting pin.

Technical specs.:

Insulator: Black glass filled polyester PCT-GF30-FR

Flammability: UL 94V-O

Contact: Brass CuZn36Pb3 (C36000)


Connecting pin Ø: 0.5 mm

Mechanical life: Min. 100 cycles

Rated current: 3 A

Contact resistance: Max. 10 mΩ

Dielectric strength: Min. 1000 V RMS

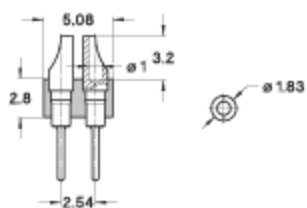

Ordering information RoHS-compliant parts

PP Plating code	Termination	Connecting pin
10	Gold 0.25 µm	Gold 0.25 µm
80	Tin	Tin

NN number of poles. Replace **NN** with the requested number of poles, e.g. 460-10-**2NN**-00-001101 for a double row version with 16 pins becomes 460-10-**216**-00-001101.


[General technical specs.](#)[View CAD](#)

480-PP-2NN-00-001101

Solder cup strip with solder tail /connecting pin: **double row.**

Availability from: 4 to 72 contacts.

Standard number of contacts 72.

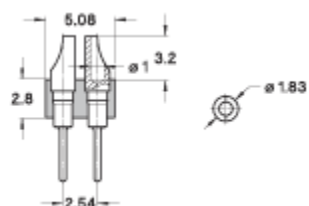

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Preci-dip:

[480-10-218-00-001101](#) [480-10-214-00-001101](#) [480-10-216-00-001101](#) [480-10-208-00-001101](#) [480-10-220-00-001101](#) [480-10-204-00-001101](#) [480-10-212-00-001101](#) [480-10-206-00-001101](#)