

AS85049/60-2G and MS3416-G Straight Shrink Boot Adapter



AS85049

CONNECTOR DESIGNATOR:

A

AS50151 Series AS34001
MIL-DTL-26482 Series II
AS81703 Series III
MIL-DTL-83723 Series I & III
40M39569, DEF 5326-3
EN 2997, EN 3646
ESC 10, ESC 11, LN 29504
NFC93422 Series HE302
PAN 6432-1, PAN 6432-2
PATT 602

Basic Part Number

Shell Size

M85049/60-2G

22

W

Finish

A = Black Anodize
W = 1000 Hr. Cadmium Olive Drab
X = Nickel Fluorocarbon Polymer
Y = Pure Dense Electrodeposited Aluminum
Z = Zinc Nickel, Black

Superseded Part Number

Basic
Part Number

Shell
Size

Style

MS3416

- 22

G

C

Finish

A = 1,000 Hr. Cadmium Olive Drab
C = Cadmium Olive Drab
N = Electroless Nickel

B

APPLICATION NOTES

- For complete dimensions see the applicable Military Specification.
- Metric dimensions (mm) are in parentheses.

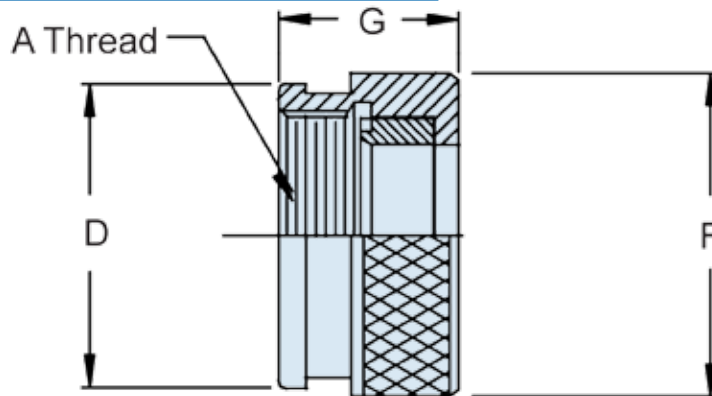


TABLE I: Shell Size, Thread and Dimensions

Shell Size	A Thread Class 2B	D Dia +.000 (0.0) -.020 (0.5)	F Dia +.000 (0.0) -.045 (1.1)	G Max
3	.562 - 24 UNEF	.709 (18.0)	.750 (19.1)	.540 (13.7)
8	.500 - 20 UNF	.657 (16.7)	.688 (17.5)	.540 (13.7)
10	.625 - 24 UNEF	.774 (19.7)	.803 (20.4)	.540 (13.7)
12	.750 - 20 UNEF	.898 (22.8)	.938 (23.8)	.540 (13.7)
14	.875 - 20 UNEF	1.024 (26.0)	1.063 (27.0)	.540 (13.7)
16	1.000 - 20 UNEF	1.152 (29.3)	1.238 (31.4)	.540 (13.7)
18	1.062 - 18 UNEF	1.243 (31.6)	1.310 (33.3)	.540 (13.7)
20	1.188 - 18 UNEF	1.370 (34.8)	1.436 (36.5)	.540 (13.7)
22	1.313 - 18 UNEF	1.443 (36.7)	1.560 (39.6)	.540 (13.7)
24	1.438 - 18 UNEF	1.618 (41.1)	1.686 (42.8)	.540 (13.7)
28	1.750 - 18 UNS	1.969 (50.0)	2.062 (52.4)	.702 (17.8)
32	2.000 - 18 UNS	2.219 (56.4)	2.312 (58.7)	.702 (17.8)
36	2.250 - 16 UN	2.469 (62.7)	2.562 (65.1)	.702 (17.8)
40	2.500 - 16 UN	2.719 (69.1)	2.812 (71.4)	.702 (17.8)
44	2.750 - 16 UN	2.969 (75.4)	3.062 (77.8)	.702 (17.8)
48	3.000 - 16 UN	3.219 (81.8)	3.312 (84.1)	.702 (17.8)
61	1.500 - 18 UNEF	1.653 (42.0)	1.748 (44.4)	.540 (13.7)

Dimensions in inches (millimeters) and are subject to change without notice.

© 2013 Glenair, Inc.

Mil-Spec Backshells

U.S. CAGE Code 06324

Printed in U.S.A.

GLENAIR, INC. • 1211 AIR WAY • GLENDALE, CA 91201-2497 • 818-247-6000 • FAX 818-500-9912
www.glenair.com B-83 E-Mail: sales@glenair.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[MS3416-14GA](#) [MS3416-14GC](#) [M85049/60-2G14N](#) [M85049/60-2G48N](#) [M85049/60-2G28N](#) [M85049/60-2G3N](#)
[M85049/60-2G61A](#) [M85049/60-2G44W](#) [M85049/60-2G48W](#) [M85049/60-2G36N](#) [M85049/60-2G3W](#) [M85049/60-](#)
[2G40N](#) [M85049/60-2G61N](#) [M85049/60-2G44N](#) [M85049/60-2G44A](#) [M85049/60-2G61W](#) [M85049/60-2G32N](#)
[M85049/60-2G40W](#) [M85049/60-2G48A](#) [MS3416-48GC](#) [MS3416-8GG](#) [MS3416-61GG](#) [MS3416-3GA](#) [MS3416-3GC](#)
[MS3416-10GA](#) [MS3416-18GG](#) [MS3416-28GG](#) [MS3416-44GN](#) [MS3416-44GA](#) [MS3416-12GN](#) [MS3416-44GC](#)
[MS3416-48EN](#) [MS3416-20GA](#) [MS3416-22GA](#) [MS3416-40GA](#) [MS3416-40GG](#) [MS3416-16GG](#) [MS3416-18GA](#)
[MS3416-32GA](#) [MS3416-36GG](#) [MS3416-36GA](#) [MS3416-61GA](#) [MS3416-24GA](#) [MS3416-28GA](#) [MS3416-20GG](#)
[MS3416-48GG](#) [MS3416-44GG](#) [MS3416-61GC](#) [MS3416-48GA](#) [MS3416-16GA](#) [MS3416-24GG](#) [MS3416-32GG](#)
[MS3416-16GN](#) [MS3416-12GG](#) [MS3416-3GG](#) [MS3416-12GA](#) [MS3416-22GG](#) [MS3416-16GC](#) [MS3416-10GG](#)
[MS3416-14GG](#)