


 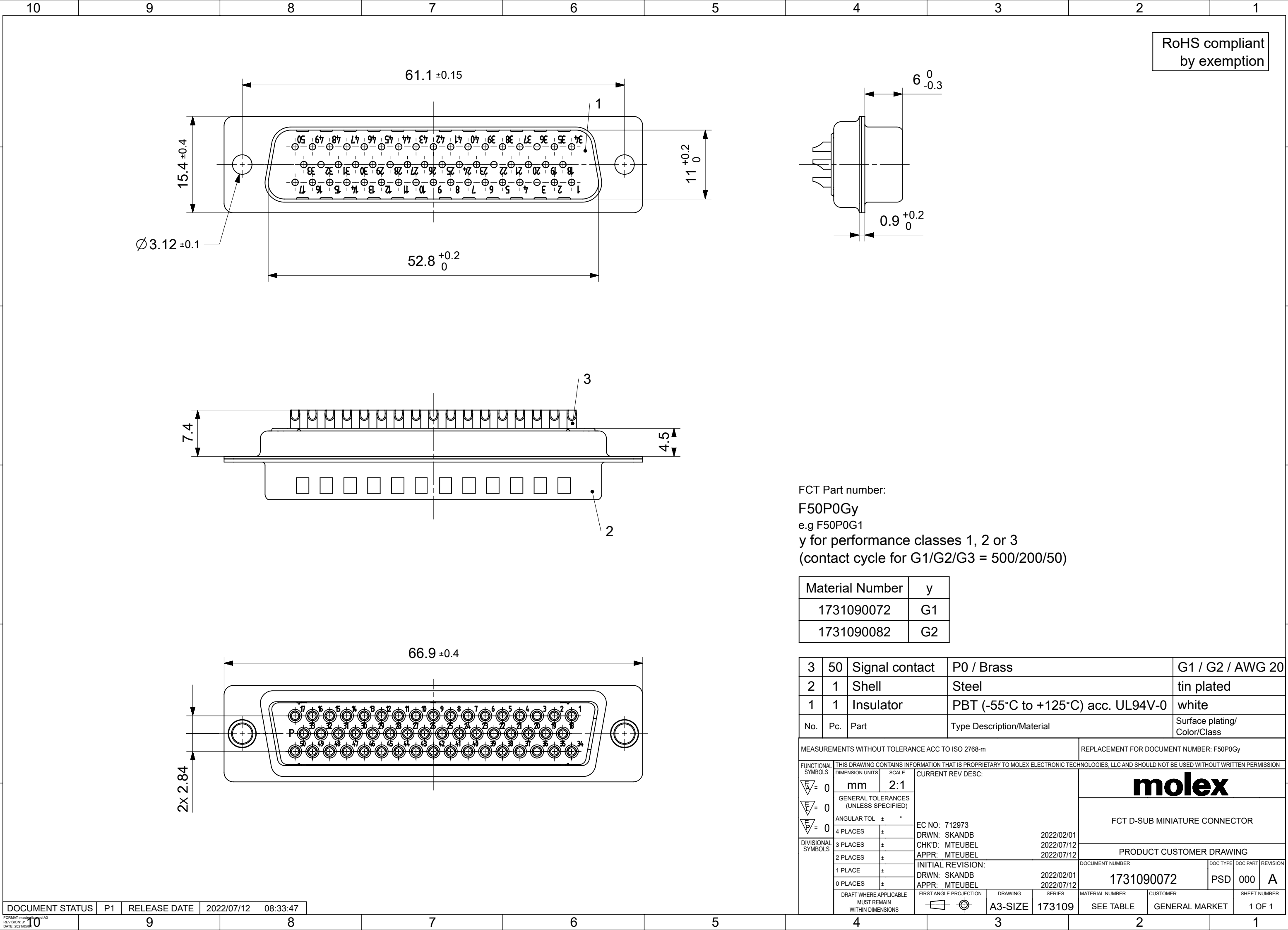


RoHS compliant
by exemption

FCT Part number:
F50P0Gy
e.g F50P0G1
y for performance classes 1, 2 or 3
(contact cycle for G1/G2/G3 = 500/200/50)

Material Number	y
1731090072	G1
1731090082	G2

3	50	Signal contact	P0 / Brass	G1 / G2 / AWG 20
2	1	Shell	Steel	tin plated
1	1	Insulator	PBT (-55°C to +125°C) acc. UL94V-0	white
No.	Pc.	Part	Type Description/Material	Surface plating/ Color/Class

MEASUREMENTS WITHOUT TOLERANCE ACC TO ISO 2768-m					REPLACEMENT FOR DOCUMENT NUMBER: F50P0Gy						
THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION											
FUNCTIONAL SYMBOLS	0	DIMENSION UNITS	SCALE	CURRENT REV DESC:			molex				
		mm	2:1								
		GENERAL TOLERANCES (UNLESS SPECIFIED)									
							ANGULAR TOL	±	°		
DIVISIONAL SYMBOLS	0	3 PLACES	±	EC NO: 712973 DRWN: SKANDB CHK'D: MTEUBEL APPR: MTEUBEL INITIAL REVISION: DRWN: SKANDB APPR: MTEUBEL			FCT D-SUB MINIATURE CONNECTOR				
		4 PLACES	±								
		2 PLACES	±								
		1 PLACE	±								
		0 PLACES	±								
DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		FIRST ANGLE PROJECTION		DRAWING	A3-SIZE	SERIES	173109	DOCUMENT NUMBER	DOC TYPE	DOC PART	REVISION
								1731090072	PSD	000	A
								MATERIAL NUMBER	CUSTOMER	SHEET NUMBER	
SEE TABLE	GENERAL MARKET	1 OF 1									