

Han FireWire module, male for patch cord

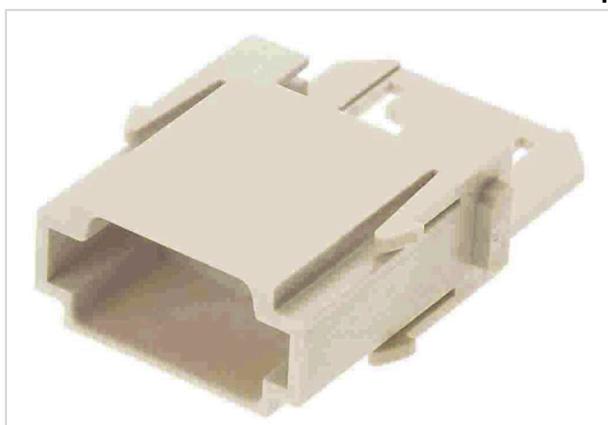


Image is for illustration purposes only. Please refer to product description.

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® FireWire module
Size of the module	Single module
Description of the module	for patch cable

Version

Gender	Male
--------	------

Technical characteristics

Rated current	1 A
Rated voltage	50 V
Rated impulse voltage	0.8 kV
Pollution degree	3
Insulation resistance	$>10^{10} \Omega$
Limiting temperature	-40 ... +85 °C
Mating cycles	≥ 500

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant

Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
UL / CSA	UL 1977 ECBT2.E235076
Approvals	DNV GL

Commercial data

Packaging size	1
Net weight	10 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140019416
ETIM	EC002312
eCl@ss	27440207 Adapter for industrial connectors (module/contact insert)