


SIGN	DATE	DESCRIPTION	APPROVER
△			
THIS IS CAD DRAWING, DO NOT REVISE MANUALLY!!!			

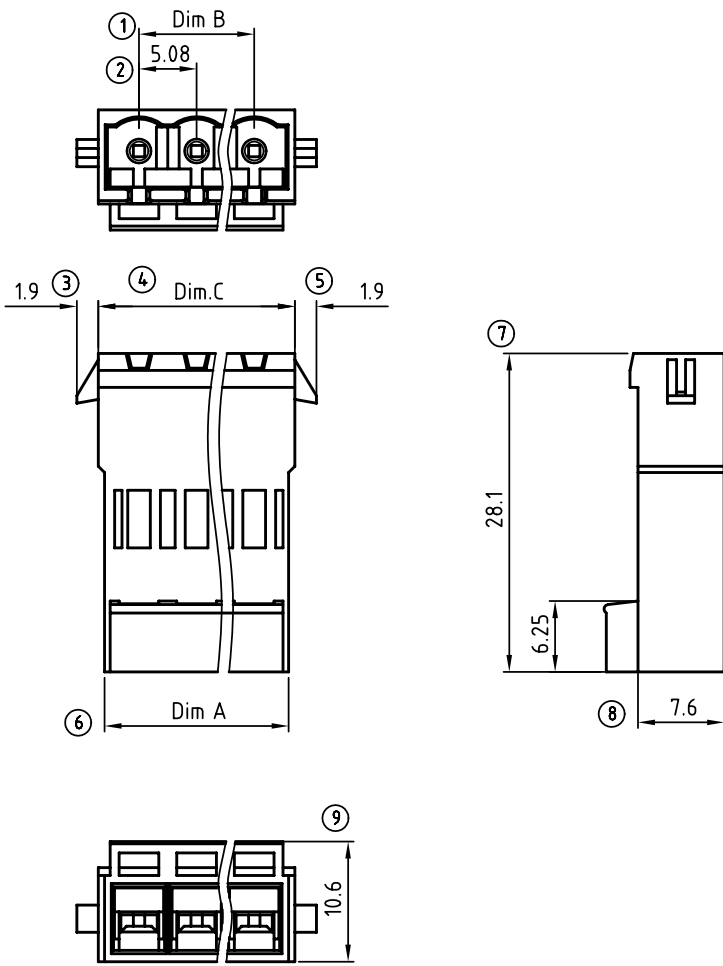

Material:

- Item :Terminal housing:Thermoplastic (UL94 V-0)

Electrical (Match with AR series)

- Voltage rating: 300V
- Current rating: 10A
- Wire range: 1.5~2.5mm²
- Withstanding Voltage: 1.6KV

KV xx 50 x 3 xxxx G

No. OF POLES ————

02 2 CONTACTS

03 3 CONTACTS

... ..

24 24 CONTACTS

Color

0 Black (RAL9005)

2 Red (RAL3001/D)

3 Orange(RAL2011/P)

4 Yellow(RAL1018/A)

5 Green(RAL6018/T)

6 Blue (RAL5015/A)

8 Grey(RAL7035/D)

G: Pb<40000ppm

0000: “@” Logo (Standard)

000A: “ANYTEK” Mark

Any special item by customer request, please contact sales department.

N = Number of poles

Dim A=Nx5.08+1.0

Dim B=(N-1)x5.08

Dim C=Nx5.08+2.1

	Dim A	Dim B	Dim C
2-6p	±0.10	±0.15	±0.15
7-12p	±0.20	±0.20	±0.20
13-16p	±0.30	±0.25	±0.25
17-24p	±0.40	±0.35	±0.35

ANYTEK				CUSTOMER COPY					
ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD									
TITLE		KV 5.08 SERIES (With Hook & High profile)							
PART NO.		KVxx50x3xxxxG		DWG NO.		8KV0004			
APPROVED		CHECKED	DESIGNED	DRAWN	CUST NO.		Tolerance		
			Kind	Kind			X.	±0.50	
			2009.12.15	2009.08.10			UNIT: mm	X.X	±0.30
							SCALE: 2/1	X.XX	±0.10
					SHEET: 01/01	REV.: B	X°	±1°	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

<u>KV0250530000G</u>	<u>KV0350530000G</u>	<u>KV0450530000G</u>	<u>KV0550530000G</u>	<u>KV0650530000G</u>	<u>KV0750530000G</u>
<u>KV0850530000G</u>	<u>KV0950530000G</u>	<u>KV1050530000G</u>	<u>KV1150530000G</u>	<u>KV1250530000G</u>	<u>KV1350530000G</u>
<u>KV1450530000G</u>	<u>KV1550530000G</u>	<u>KV1650530000G</u>	<u>KV1750530000G</u>	<u>KV1850530000G</u>	<u>KV1950530000G</u>
<u>KV2050530000G</u>	<u>KV2150530000G</u>	<u>KV2250530000G</u>	<u>KV2350530000G</u>	<u>KV2450530000G</u>	<u>KV0450030000G</u>