


## COAXIAL CONNECTOR, SMA, 50 Ohm, Straight cable plug (male)

11\_SMA-50-3-73/-99\_N

### Properties

- Excellent return loss
- Intermateable with PC3.5 and SK
- Applicable in frequencies up to 18 GHz

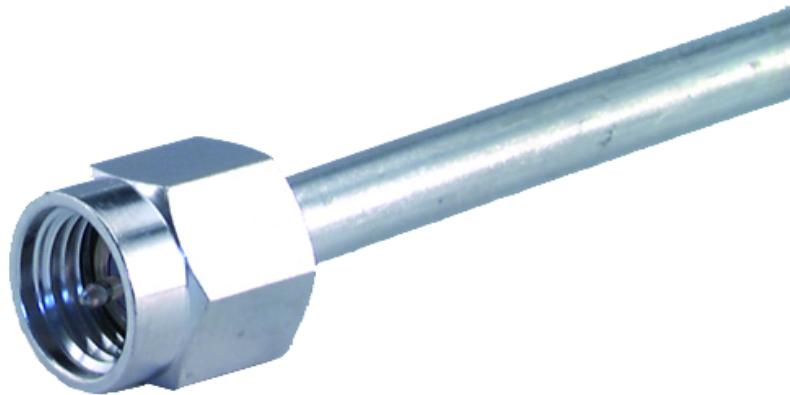

CE UK  
CA

### Product configuration

Interface type	Gender	Standard
SMA	plug	IEC 60169-15_MIL-STD-348A/310_CECC 22110

### Interface and material data

Piece parts	Material	Plating
Outer conductor	Stainless Steel	Passivated (Plating)
Body	Stainless Steel	Passivated (Plating)
Coupling nut	Stainless Steel	Passivated (Plating)
Gasket	PFA / PTFE	

### Electrical data

Impedance	50 Ω
Interface frequency	18 GHz

### Mechanical data

Weight	0.0021 kg
Mating cycles	500
Cable entry centre contact	plugged
Cable entry outer contact	crimped

### Environmental data

Operation temperature	-65 °C ... 165°C
-----------------------	------------------

**COAXIAL CONNECTOR, SMA, 50 Ohm, Straight cable plug (male)**  
11\_SMA-50-3-73/-99\_N

**Ordering Information Table**

Item number	Item description	Packaging type	Packaging information
22646221	11_SMA-50-3-73/-99_NE	Single	
23010638	11_SMA-50-3-73/-99_NH	Tray	changed to Tray (Code H for bag must remain)

**Suitable cables**

Cable group	Y5 - 3 mm / 50 Ohm
-------------	--------------------

**Additional Information**

Only as assembly	No
------------------	----

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.  
DOCUMENT PIM-P3446 / Date of publication: 25.11.2023 / uncontrolled copy