

Han FireWire modul female gender changer

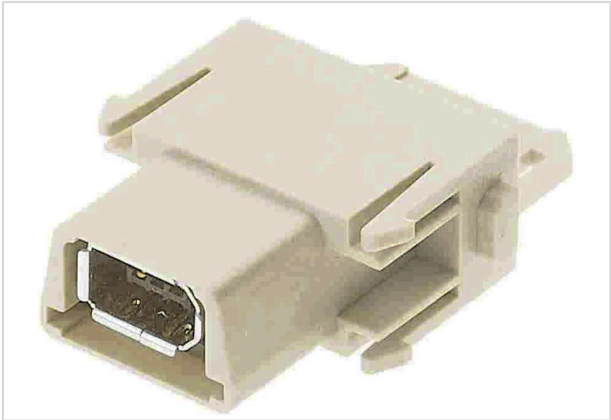


Image is for illustration purposes only. Please refer to product description.

| | |
|--------------------|---|
| Part number | 09 14 001 4711 |
| Specification | Han FireWire modul female gender changer |
| HARTING eCatalogue | https://b2b.harting.com/09140014711 |

Identification

| | |
|---------------------------|----------------------|
| Category | Modules |
| Series | Han-Modular® |
| Type of module | Han® FireWire module |
| Size of the module | Single module |
| Description of the module | for patch cable |

Version

| | |
|--------------------|--------|
| Gender | Female |
| Number of contacts | 6 |

Technical characteristics

| | |
|-----------------------|-------------------|
| Rated current | 1 A |
| Rated voltage | 50 V |
| Rated impulse voltage | 0.8 kV |
| Pollution degree | 3 |
| Insulation resistance | $>10^{10} \Omega$ |
| Limiting temperature | -40 ... +85 °C |
| Mating cycles | ≥ 500 |

Material properties

| | |
|---|------------------------|
| Material (insert) | Polycarbonate (PC) |
| Colour (insert) | RAL 7032 (pebble grey) |
| Material flammability class acc. to UL 94 | V-0 |



Pushing Performance
Since 1945

Material properties

| | |
|--------------------------------------|--|
| RoHS | compliant with exemption |
| RoHS exemptions | 6(c): Copper alloy containing up to 4 % lead by weight |
| ELV status | compliant with exemption |
| China RoHS | 50 |
| REACH Annex XVII substances | Not contained |
| REACH ANNEX XIV substances | Not contained |
| REACH SVHC substances | Yes |
| REACH SVHC substances | Lead |
| ECHA SCIP number | 5dbb3851-b94e-4e88-97a1-571845975242 |
| California Proposition 65 substances | Yes |
| California Proposition 65 substances | Lead |
| Fire protection on railway vehicles | EN 45545-2 (2020-08) |
| Requirement set with Hazard Levels | R22 (HL 1-3) R23 (HL 1-3) |

Specifications and approvals

| | |
|----------------|--------------------------|
| Specifications | IEC 60664-1 IEC 61984 |
| UL / CSA | UL 1977 ECBT2.E235076 |
| Approvals | DNV GL |

Commercial data

| | |
|--------------------------------|--|
| Packaging size | 1 |
| Net weight | 16.34 g |
| Country of origin | Germany |
| European customs tariff number | 85389099 |
| GTIN | 5713140019485 |
| ETIM | EC000438 |
| eCl@ss | 27440218 Module for industrial connectors (data) |