

JTPQ00R (MS27497) Series II – Crimp

Wall Mounting Receptacle

(Back Panel Mounting)



PART

Part number reference. To complete, see how to order pages 62-66.


Connector Type	Shell Style	Service Class	Shell Size & Insert Arrg	Contact Type	Alternate Position	Special Variations
JTPQ/JTPSQ	00	RT	22-2	P	A	(XXX)

Military


MS Number	Service Class	Shell Size	Finish	Insert Arrg	Contact Style (P or S)	Alternate Position
MS27497	E	14	A	18	P	A

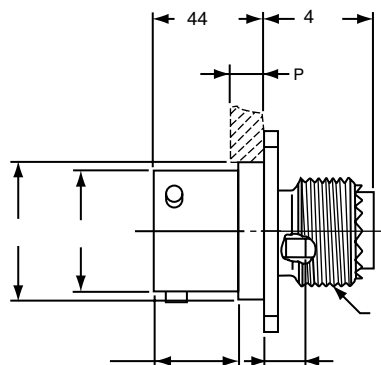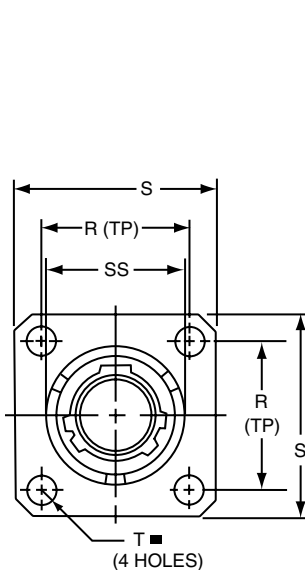


* JTPQ00RT-XX-XXX (MS27497T)
** JTPSQ00RT-XX-XXX

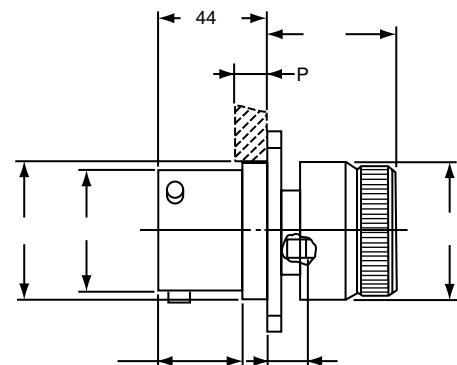

* JTPQ00RE-XX-XXX (MS27497E)

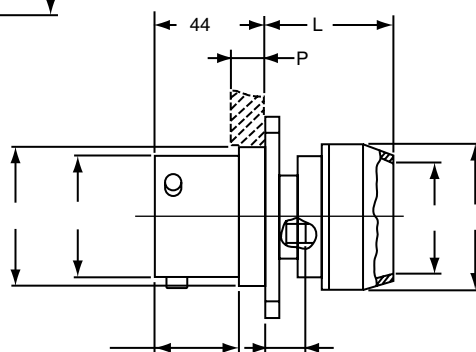

* JTPQ00RP-XX-XXX (MS27497P)

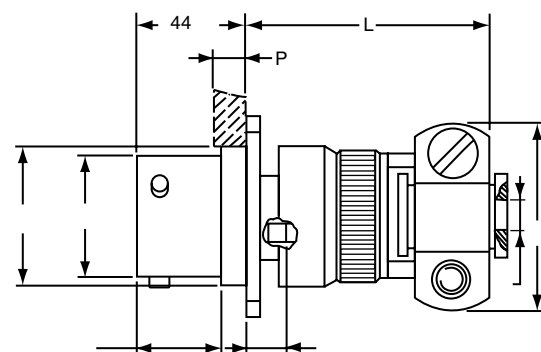

* JTPQ00RE-XX-XXX (SR)

⊕ .005 DIA (M)

* Standard Junior Tri-Lock

** High temperature version

Shell Size	F Dia. +.010 -.025	F' Dia. ±.010	L Max.	L' Max.	N +.001 -.005	P Max. Panel Thickness	R (TP)	S ±.016	T ±.005	V Thread UNEF Class 2A (Plated)	AD Dia. ±.005	KK Max.	KK' Dia. Max.	KK² Dia. Max.	SS Dia. +.000 -.016
8	.125	.444	1.140	.468	.473	.142	.594	.812	.120	.4375-28	.516	.781	.625	.578	.563
10	.188	.558	1.140	.468	.590	.142	.719	.938	.120	.5625-24	.633	.844	.750	.703	.680
12	.312	.683	1.140	.468	.750	.142	.812	1.031	.120	.6875-24	.802	.969	.875	.828	.859
14	.375	.808	1.375	.468	.875	.142	.906	1.125	.120	.8125-20	.927	1.094	1.000	.953	.984
16	.500	.909	1.375	.468	1.000	.142	.969	1.219	.120	.9375-20	1.052	1.154	1.125	1.078	1.108
18	.625	1.034	1.375	.468	1.125	.142	1.062	1.312	.120	1.0625-18	1.177	1.406	1.250	1.203	1.233
20	.625	1.159	1.375	.468	1.250	.142	1.156	1.438	.120	1.1875-18	1.302	1.406	1.375	1.328	1.358
22	.750	1.284	1.516	.468	1.375	.142	1.250	1.562	.120	1.3125-18	1.427	1.594	1.500	1.453	1.483
24	.800	1.409	1.500	.540	1.500	.142	1.375	1.688	.147	1.4375-18	1.552	1.688	1.625	1.578	1.610

All dimensions for reference only.

38999

III

HD

Dualok

II

I

SJT

Accessories

Aquacon

Herm/Seal

PCB

HIGH
SPEED

Fiber
Optics

Contacts
Connectors
Cables

EMI Filter
Transient

26482
Matrix 2

83723 III
Matrix | Pyle

26500
Pyle

5015
Crimp Rear
Release
Matrix

22992
Class I

Back-
Shells

Options
Others

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

[MS27508E20B41B](#) [MS27508E20B41BA](#) [MS27474T14B18B](#) [MS27497T14B18A](#) [MS27508E16B35AA](#)
[MS27497T18F53S](#) [MS27508E24B61B](#) [MS27497T14A35SB](#) [MS27497T16F35SB](#) [MS27497T20B2SB](#)
[MS27497T20B2SA](#) [MS27474E22B55A](#) [MS27497E10B35P](#) [MS27497E12B4P](#) [MS27497E12B98P](#)
[MS27497E14B18S-LC](#) [MS27497E14F35P](#) [MS27497E14F35S](#) [MS27497E16B35P](#) [MS27497E16B55P](#)
[MS27497E16F35P](#) [MS27497E24F35SA](#) [MS27497T10A35S](#) [MS27497T10B35P-LC](#) [MS27497T10B35S-LC](#)
[MS27497T10B99P-LC](#) [MS27497T10F35P](#) [MS27497T12B22B](#) [MS27497T12B22P](#) [MS27497T12B22S](#)
[MS27497T12B35S-LC](#) [MS27497T12B3S](#) [MS27497T12B98P-LC](#) [MS27497T12B98S-LC](#) [MS27497T14B18P-LC](#)
[MS27497T14B35B](#) [MS27497T14B35S](#) [MS27497T14B35SA-LC](#) [MS27497T14B35S-LC](#) [MS27497T14B97B](#)
[MS27497T14B97P-LC](#) [MS27497T16A55S](#) [MS27497T16B26P](#) [MS27497T16B35P-LC](#) [MS27497T16B35S-LC](#)
[MS27497T16B42P](#) [MS27497T16B42PA](#) [MS27497T16B6S-LC](#) [MS27497T16B8P](#) [MS27497T16B99P-LC](#)
[MS27497T16F26S-LC](#) [MS27497T18B28P-LC](#) [MS27497T18B32P](#) [MS27497T18B32S](#) [MS27497T18B35P-LC](#)
[MS27497T18B35S-LC](#) [MS27497T18B96P](#) [MS27497T18F32P](#) [MS27497T20B16S-LC](#) [MS27497T20B35P-LC](#)
[MS27497T20B35SA-LC](#) [MS27497T20B41P-LC](#) [MS27497T20B41S-LC](#) [MS27497T20F35P](#) [MS27497T22B2P](#)
[MS27497T22B2S](#) [MS27497T22B35P-LC](#) [MS27497T22B55P-LC](#) [MS27497T24B19P](#) [MS27497T24B19P-LC](#)
[MS27497T24B35P-LC](#) [MS27497T24B35SA-LC](#) [MS27497T24B35SC-LC](#) [MS27497T24B4PC-LC](#) [MS27497T24B61PA-](#)
[LC](#) [MS27497T24B61S-LC](#) [MS27497T8B6A](#) [MS27497T8B6P](#) [MS27508E10A35BB](#) [MS27508E10A35BC](#)
[MS27508E10B35A](#) [MS27508E10B35PA](#) [MS27508E12B35A](#) [MS27508E14B35A](#) [MS27508E14B35B](#)
[MS27508E16A8B](#) [MS27508E16B35B](#) [MS27508E18B35B](#) [MS27508E20B35A](#) [MS27508E20B35AA](#)
[MS27508E20B35AB](#) [MS27508E20B35AC](#) [MS27508E20B35AD](#) [MS27508E20B35B](#) [MS27508E22B35A](#)
[MS27508E22B35AB](#) [MS27508E22B35B](#) [MS27508E22B35BB](#) [MS27508E24B61A](#) [MS27508E24B61AA](#)