

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1731120190

Status:

Active

Overview:

FCT D-Sub Connectors


Description:

FCT Coaxial Contact, 3 Pins, Male, Right-Angle, PCB Through Hole, 50 Ohms, 1.30µm Gold Plating, for D-sub Shell Size 5 Only

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	D-Sub Products
Series	173112
Brochure Order No	987651-9941
Contact Type	Coaxial
Exclude SD Check	Yes
Overview	FCT D-Sub Connectors
Product Category	Contacts
Product Name	FCT Products
Type	Mixed Layout
UPC	889056489454
Physical	
Durability (mating cycles max)	500
Gender	Male
Material - Contact	Copper Alloy
Net Weight	3.600/g
Orientation	Right-Angle
Packaging Type	Tube
Plating - Contact	Gold over Nickel
Plating min - Mating	0.800µm
Plating min - Termination	1.300µm
Temperature Range - Operating	-55° to +135°C
Termination Style	Through Hole
Electrical	
Current - Maximum per Contact	2.0A
Impedance	50Ω
Material Info	
Engineering Number	FME020P102

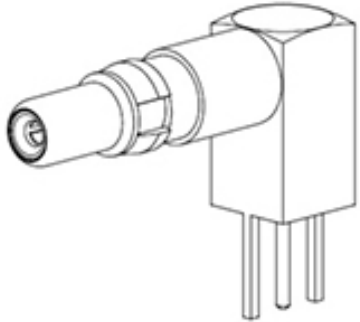

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Relevant	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

173112 Series

Use With

FCT Mixed Layout Connectors, D-Sub Shell Size 5 Only

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION