

Part Number : 1731120734


Product Description : FCT Machined Contact, Female, Crimp, 0.20µm Gold Plating, Split Tine, 28-26 AWG, 1000 Pieces

Series Number : 173112

Status : Active

Product Category : D-Sub Contacts

Engineering Number : FK20SL26-02V-6096

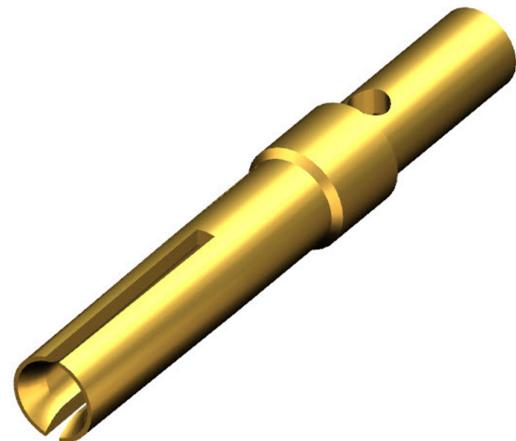

## Documents & Resources

### Drawings

1731120734\_sd.pdf

### Specifications

1731120004-PK-000.pdf

2195600650-000.pdf

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	ⓘ
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Contains Lead per D(2023)8585-DC (23 Jan 2024)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

Status	Active
Category	D-Sub Contacts
Series	173112
Description	FCT Machined Contact, Female, Crimp, 0.20µm Gold Plating, Split Tine, 28-26 AWG, 1000 Pieces
Contact Type	Machined Crimp
Magnetic	Yes
Product Name	FCT Products
Type	Standard Density
UPC	191128856119

#### Electrical

Current - Maximum per Contact	7.5A
-------------------------------	------

#### Physical

Durability (mating cycles max)	200
Gender	Female
Material - Contact	Copper Alloy
Material - Plating Mating	Gold over Nickel
Material - Plating Termination	Gold over Nickel
Net Weight	0.100/g
Orientation	Straight
Packaging Type	Bag
Plating min - Mating	0.200µm
Plating min - Termination	0.200µm
Temperature Range - Operating	-55° to +130°C

---

Termination Style	Crimp
Wire Size (AWG)	26, 28

---

## Use with Part(s)

Description	Part Number
Use With	FCT Standard-Density Connectors

---

## Application Tooling

### Global

Description	Part Number
FCT Hand Crimp Tool, Mini Frame, 8-Step Adjust	<u>1731121730</u>
FCT Installation and Removal Tool for D-Subs	<u>1731121744</u>
FCT Locator for Size 20 Contacts, Socket	<u>1731121763</u>

---

This document was generated on Oct 14, 2024