



MTMM-124-14-S-S-600

MTMM-114-05-T-Q-225

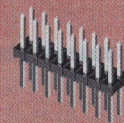

MTMM-108-07-G-D-200

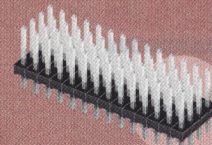

MODIFIED HEADER MTMM SERIES

SPECIFICATIONS

For complete specifications
see www.samtec.com?MTMM

Insulator Material:

Black Liquid Crystal Polymer

Terminal Material:

Phosphor Bronze

Current Rating:

3A @ 80°C ambient

Operating Temp Range:

-65°C to +105°C with Tin;

-65°C to +125°C with Gold

Max Processing Temp:

230°C for 60 seconds


Plating:

Sn or Au over 50µ" (1,27µm) Ni




FILE NO. E111594

Mates with:
CLT, SQT, SQW, ESQT,
TLE, SMM, MMS, TCSD

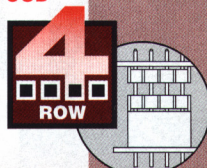


Board Stacking

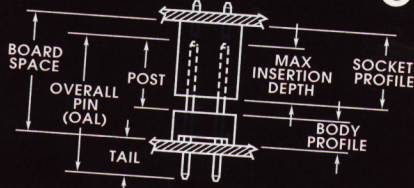

Choice of
single, double or
quad row

Specify post
height in (0,13mm)
.005" increments

 ALSO AVAILABLE




Paste In Hole
(PIH) processing.
Contact Samtec
ASP Group.



MTMM - 1 NO. PINS PER ROW - LEAD STYLE - PLATING OPTION - ROW OPTION - POST HEIGHT - OPTION

01 thru 50

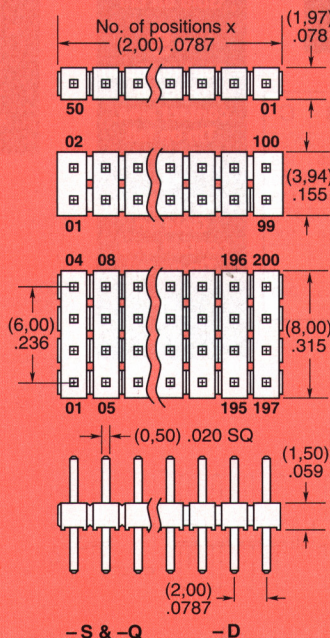

Specify
LEAD
STYLE
from
chart.

-G
= 20µ" (0,51µm)
Gold post
Gold flash on tail

-S
= 30µ" (0,76µm)
Gold post,
Tin on tail

-T
= Tin

-S
= Single
Row
-D
= Double
Row
-Q
= Quad
Row

- "XXX"
= Post Height
in inches
(0,13mm) .005"
increments
Example:
-070
= (1,78mm)
.070"

- "XXX"
= Polarized
Position
Specify
position of
omitted pin

LEAD STYLE	OAL
-02	(6,48) .255
-03	(7,67) .302
-04	(8,20) .323
-05	(9,58) .377
-06	(10,08) .397
-07	(11,58) .456
-08	(12,09) .476
-09	(13,59) .535
-10	(14,10) .555
-11	(15,09) .594
-12	(15,60) .614
-13	(17,09) .673
-14	(19,08) .751
-15	(21,08) .830

Note: This Series is non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 • Fax: 812-948-5047
SAMTEC FRANCE • Tel: 01 60 95 06 60 • Fax: 01 60 95 06 61
SAMTEC SCANDINAVIA • Tel: +46-84477280 • Fax: +46-87420413
SAMTEC CHINA • Tel: 86-21-5385-4089 • Fax: 86-21-5385-4047
SAMTEC HONG KONG • Tel: 852-26904858 • Fax: 852-26904842
SAMTEC UK • Tel: 01236 739292 • Fax: 01236 727113
SAMTEC ITALY • Tel: 39 039 6890337 • Fax: 39 039 6890315
SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 • Fax: 65 6841-1502
SAMTEC TAIWAN • Tel: 886-02-2364-6077 • Fax: 886-02-2367-9531
SAMTEC ANZ • Tel: 613 9512 7747 • Fax: 613 9512 7745
SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0 • Fax: +49 (0) 89 / 89460-299
SAMTEC ISRAEL • Tel: 972-3-7526600 • Fax: 972-3-7526690
SAMTEC JAPAN • Tel: 81-424-42-8318 • Fax: 81-424-42-8319

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[MTMM-110-03-T-D-138](#) [MTMM-116-15-T-D-700](#) [MTMM-107-08-G-D-270](#) [MTMM-105-06-T-D-230](#) [MTMM-108-06-S-D-160](#) [MTMM-110-05-S-D-120](#) [MTMM-120-03-S-D-126](#) [MTMM-110-05-T-D-220](#) [MTMM-108-07-T-D-265](#) [MTMM-110-14-G-D-500](#) [MTMM-105-02-T-D-000](#) [MTMM-110-06-S-D-190](#) [MTMM-108-06-S-D-250](#) [MTMM-116-04-S-D-125](#) [MTMM-120-04-T-D-010](#) [MTMM-105-10-T-D-250](#) [MTMM-107-15-T-D-740](#) [MTMM-105-15-T-D-400](#) [MTMM-110-12-G-D-000](#) [MTMM-115-04-S-D-210](#) [MTMM-105-05-G-D-235](#) [MTMM-107-13-G-D-500](#) [MTMM-125-05-G-D-240](#) [MTMM-113-05-G-D-150](#) [MTMM-110-13-S-D-510](#) [MTMM-112-15-G-D-640](#) [MTMM-125-03-S-D-130](#) [MTMM-140-14-G-D-330](#) [MTMM-117-03-S-D-000](#) [MTMM-120-09-T-D-000](#)