

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0014441204

Status:

Active

Overview:

C-Grid® / SL™ Products

Description:

2.54mm (.100") Pitch SL™ Insulation Displacement Connector Assembly, Male, Single Row, Version D, Back Ribs, for Wire Size 24, 0.38µm (15µ") Gold (Au), 4 Circuits

Documents:

- [3D Model](#)
- [Drawing \(PDF\)](#)
- [Product Specification PS-70400 \(PDF\)](#)
- [Product Specification PS-70475 \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family

Series

Comments

Component Type

Glow-Wire Compliant

Overview

Product Name

Ribbon Cable / Wire Trap Connectors

70475

Terminals Preloaded

Housing

No

C-Grid® / SL™ Products

SL™

Physical

Circuits (Loaded)

Color - Resin

Durability (mating cycles max)

Entry Angle

Flammability

Lock to Mating Part

Material - Metal

Material - Plating Mating

Material - Plating Termination

Material - Resin

Number of Rows

PCB Retention

Packaging Type

Pitch - Mating Interface (in)

Pitch - Mating Interface (mm)

Plating min: Mating (µin)

Plating min: Mating (µm)

Plating min: Termination (µin)

Plating min: Termination (µm)

Polarized to Mating Part

Stackable

Surface Mount Compatible (SMC)

Temperature Range - Operating

Termination Interface: Style

Wire Insulation Diameter

Wire Size AWG

Wire/Cable Type

Wire/Cable Type

4

Black

50

Vertical

94V-0

None

Phosphor Bronze

Gold

Tin

Polyester Alloy

1

None

Tube

0.100 In

2.54 mm

15

0.38

75

1.91

No

Yes

N/A

-40°C to +105°C

IDT or Pierce

1.35mm (.053") max.

24

Discrete Wire

Ribbon Cable

Electrical

CSA

Current - Maximum

UL

Voltage - Maximum


LR19980

3A

E29179

250V

Material Info

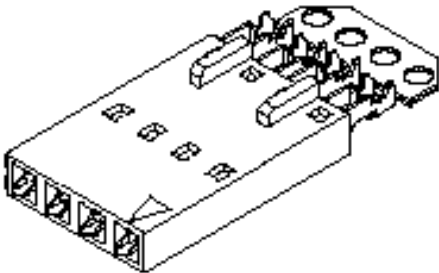

Series image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

70475 Series

Mates With

70004 Interim Clip (Single Row), 70013 Interim Clip (Dual Row)

Use With

7307 Tinned 28AWG, 7767 Topcoat 28AWG, 24241 Tinned 26AWG, 8996 Topcoat 26AWG, 24226 Tinned 24AWG, 8997 Topcoat 24AWG, 24369 High Flex 26AWG, 24389 High Flex 24AWG

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
IDT Discrete	0621000700
Handtool Module for SL™	

Old Part Number	A-70475-0598
Reference - Drawing Numbers	
Product Specification	PS-70400
Product Specification	PS-70475
Sales Drawing	SD-70475-0***
Sales Drawing	SDA-70475-0596-0619

This document was generated on 12/07/2009

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION