

HC-B-TA-M20-PLR-BK - Adapter



1414243

<https://www.phoenixcontact.com/us/products/1414243>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Plastic thread adapter with bayonet lock, for EVO housing series B, M20 thread

Commercial data

Item number	1414243
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF57
Product key	BF7APL
Catalog page	Page 659 (C-2-2019)
GTIN	4055626021966
Weight per piece (including packing)	19.9 g
Weight per piece (excluding packing)	19 g
Customs tariff number	85389099
Country of origin	PL

HC-B-TA-M20-PLR-BK - Adapter

1414243

<https://www.phoenixcontact.com/us/products/1414243>



Technical data

Product properties

Product type	Thread adapter
Application	Bayonet B - metric
Type of the screw connection	M20


Data management status

Article revision	00
------------------	----

Connection data

Tightening torque	... 6 Nm
-------------------	----------

Dimensions

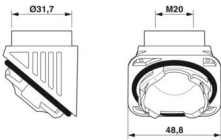Dimensional drawing	
Thread type on seal side	M20

Internal dimensions

Length of internal thread	10 mm
---------------------------	-------

Material specifications

Material	PA
Flammability rating according to UL 94	V0
Seal material O-ring	NBR
Housing material	PA

Mechanical properties

Mechanical data

Type of the screw connection	M20
------------------------------	-----

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
Ambient temperature (operation)	-40 °C ... 100 °C

Mounting

Assembly note	Bayonet locking max. 3x can be removed The plastic thread adapter does not establish an electrical connection between the cable gland and connector housing. For this reason, only plastic cable protection systems or plastic cable glands may be used.
---------------	---

HC-B-TA-M20-PLR-BK - Adapter


1414243

<https://www.phoenixcontact.com/us/products/1414243>



Drawings

Dimensional drawing

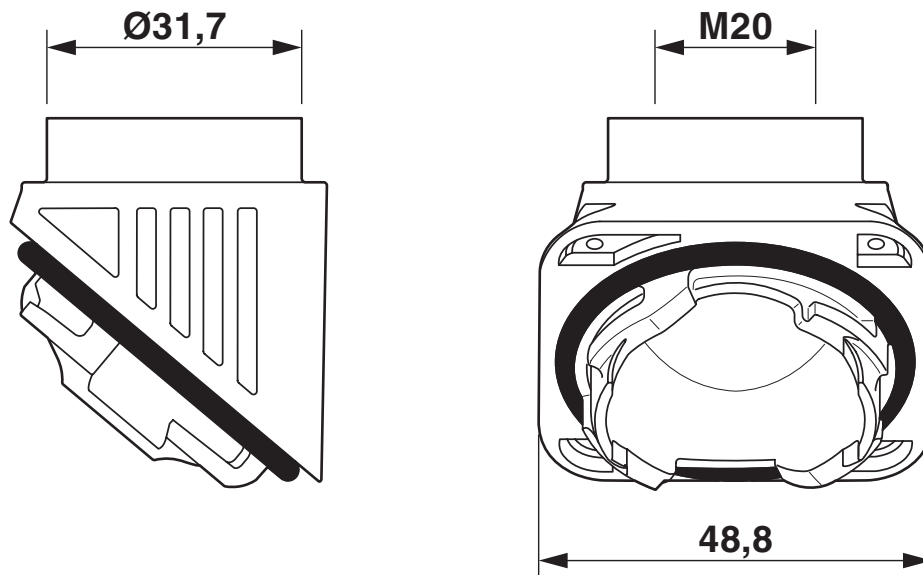

Dimensional drawing

HC-B-TA-M20-PLR-BK - Adapter



1414243

<https://www.phoenixcontact.com/us/products/1414243>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1414243>

**DNV**
Approval ID: TAE000037S

**cUL Recognized**
Approval ID: E255026

**UL Recognized**
Approval ID: E255026

**EAC**
Approval ID: RU C-DE.AI30.B.01102

cULus Recognized

HC-B-TA-M20-PLR-BK - Adapter



1414243

<https://www.phoenixcontact.com/us/products/1414243>

Classifications

ECLASS

ECLASS-11.0	27144432
ECLASS-12.0	27140801
ECLASS-13.0	27140801

ETIM

ETIM 9.0	EC000441
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

HC-B-TA-M20-PLR-BK - Adapter



1414243
<https://www.phoenixcontact.com/us/products/1414243>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com