

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731130093](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT High-Density D-Sub Connector, Female, Straight, PCB Through Hole, Gold Plating, 6.60mm Snap-in Bolt, 44 Circuits


Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	D-Sub Products
Series	173113
Brochure Order No	987651-9941
Exclude SD Check	Yes
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	High Density
UPC	889056490061

Physical	
Circuits (Loaded)	44
Circuits (maximum)	44
Color - Resin	Black
Durability (mating cycles max)	50
Gender	Female
Material - Contact	Copper Alloy
Material - Resin	PBT
Material - Shell	Steel
Net Weight	12.800/g
Number of Rows	3
Orientation	Straight
PC Tail Length	9.50mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Thread-In
Pitch - Mating Interface	1.98mm
Pitch - Termination Interface	1.98mm
Plating - Contact	Gold over Nickel
Plating - Shell	Tin
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +105°C
Termination Style	Through Hole
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20

Electrical	
Current - Maximum per Contact	3.0A

Material Info

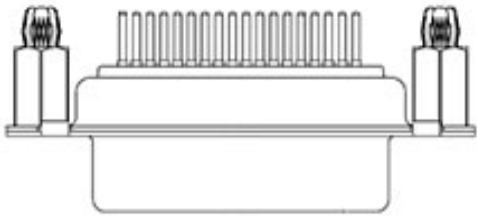

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[173113 Series](#)

Mates With

FCT High-Density D-Sub, Size 3, 44 Position, Plug

This document was generated on 07/24/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION