


COAXIAL CONNECTOR, UHF, X Ohm, Straight bulkhead receptacle, jack (female)

22_UHF-0-0-1/033_-

Properties

- Mateable with 4 mm banana plugs
- Applicable in frequencies up to 200 MHz

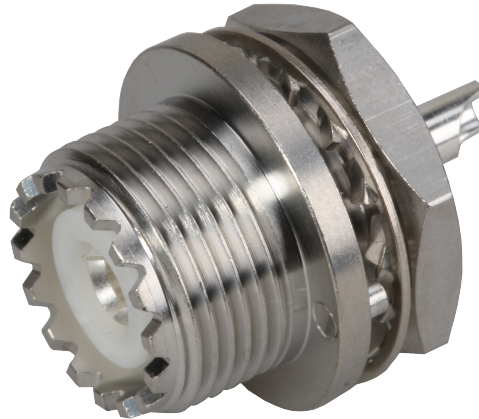

Product configuration

Interface type	Gender	Standard
UHF	jack	IEC 60169-12

Interface and material data

Piece parts	Material	Plating
Centre contact	Brass	Silver Plating
Outer conductor	Brass	SUCOPLATE (R) Plating
Body	Brass	SUCOPLATE (R) Plating
Insulator	PP (Polypropylene)	
Fastening nut	Brass	SUCOPLATE (R) Plating
Washer	Bronze	SUCOPLATE (R) Plating

Electrical data

Interface frequency	0.2 GHz
---------------------	---------

Mechanical data

Weight	0.0203 kg
Mating cycles	500
Flange type	round flange / others
Tab style	solder end

Environmental data

Operation temperature	-55 °C ... 165 °C
-----------------------	-------------------

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.
DOCUMENT PIM-P2758 / Date of publication: 26.11.2023 / uncontrolled copy