


Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

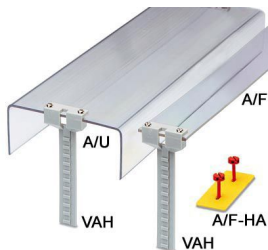

Flat-ribbon cover, for covering terminal strips, 2 mm thick, 10 cm wide, an additional requirement are 2 E/UK end brackets and 2 adjustable VAH cover holders. The max. supply length is 100 cm

## Commercial data

Item number	1004898
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BH84
Product key	BH8412
GTIN	4017918012274
Weight per piece (including packing)	270 g
Weight per piece (excluding packing)	270 g
Customs tariff number	39205100
Country of origin	DE

Technical data

Product properties

Product type	Cover profile
--------------	---------------

Dimensions

Width	100 mm
Length	1 m

Material specifications

Color	transparent
Material	Polycarbonate PC
Flammability rating according to UL 94	V2

## Classifications

### ECLASS

ECLASS-11.0	27141192
ECLASS-12.0	27141192
ECLASS-13.0	27141192

### ETIM

ETIM 9.0	EC004592
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

1004898  
<https://www.phoenixcontact.com/us/products/1004898>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2024 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)