



PT07 CE SP07 CE


jam nut receptacle

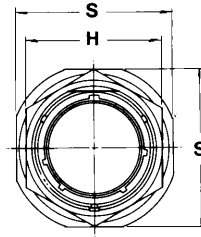


TERMINATION ASSEMBLIES
"CE" (SR) Strain Relief

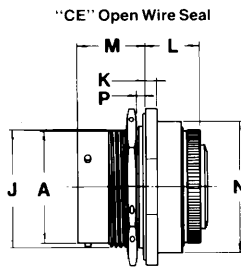

PT07CE-XX-XXX
SP07CE-XX-XXX

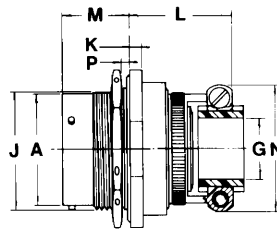

PT07CE-XX-XXX (SR)
SP07CE-XX-XXX (SR)

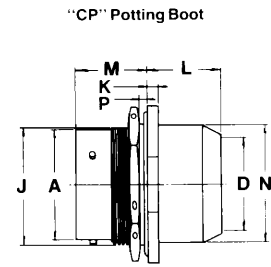

PT07CP-XX-XX
SP07CP-XX-XXX

All lock wire holes are .044 Dia. Min.

Shell Size	Receptacle Front View												Receptacle Side View									
			A Dia.		J Flat		K		M		Panel Thickness		Class "CE"		Class "CE" (SR)			Class "CP"				
	H Hex. +.017 -.016	S ±.016	+.001 -.005	+.000 -.010	±.016	±.005	Min.	Max.	L Max.	N Max.	G Dia.	L Max.	N Max.	L Max.	N Dia. Max.	D Dia. Min.						
8	.750	.938	.473	.530	.125	.696	.062	.125	.827	.730	.125	1.297	.797	.875	.608	.327						
10	.875	1.062	.590	.655	.125	.696	.062	.125	.827	.855	.188	1.297	.859	.875	.734	.444						
12	1.062	1.250	.750	.818	.125	.696	.062	.125	.827	.980	.312	1.297	.984	.875	.858	.558						
14	1.188	1.375	.875	.942	.125	.696	.062	.125	.827	1.105	.375	1.297	1.109	.875	.984	.683						
16	1.312	1.500	1.000	1.066	.125	.696	.062	.125	.827	1.230	.500	1.422	1.172	.875	1.110	.808						
18	1.438	1.625	1.125	1.191	.125	.696	.062	.125	.827	1.355	.625	1.422	1.422	.875	1.234	.909						
20	1.562	1.812	1.250	1.316	.156	.884	.062	.250	.733	1.511	.625	1.328	1.422	.969	1.360	1.034						
22	1.688	1.938	1.375	1.441	.156	.884	.062	.250	.733	1.636	.750	1.328	1.609	.969	1.484	1.159						
24	1.812	2.062	1.500	1.566	.156	.917	.062	.250	.762	1.761	.800	1.422	1.703	.969	1.610	1.284						

All dimensions for reference only.