

**RIM 3 6/24VUC GN**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**Product image**

Similar to illustration

**General ordering data**

Version	RIDERSERIES RCL, LED module, Rated control voltage: 6...24 V UC, Plug-in connection
Order No.	<a href="#">8713750000</a>
Type	RIM 3 6/24VUC GN
GTIN (EAN)	4032248390120
Qty.	10 pc(s).

Creation date September 18, 2022 3:40:12 AM CEST

Catalogue status 09.09.2022 / We reserve the right to make technical changes.

**RIM 3 6/24VUC GN****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data****Dimensions and weights**

Depth	34.5 mm	Depth (inches)	1.358 inch
Height	9 mm	Height (inches)	0.354 inch
Width	12.5 mm	Width (inches)	0.492 inch
Net weight	3 g		

**Temperatures**

Storage temperature	-40 °C...70 °C	Operating temperature	-40 °C...70 °C
Humidity	40 °C / 93 % rel. humidity, no condensation		

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1
------------	----------------

**Rated data UL**

Certificate No. (cURus)	E223759
-------------------------	---------

**Control side**

Rated control voltage	6...24 V UC	Status indicator	Green LED
-----------------------	-------------	------------------	-----------

**General data**

Colour	black
--------	-------

**Further details of approvals / standards**

Standards	UL508	Certificate No. (cURus)	E223759
-----------	-------	-------------------------	---------

**Connection data**

Wire connection method	Plug-in connection
------------------------	--------------------

**Classifications**

ETIM 6.0	EC002586	ETIM 7.0	EC002586
ETIM 8.0	EC002586	ECLASS 9.1	27-37-10-10
ECLASS 10.0	27-37-10-10	ECLASS 11.0	27-37-16-92
ECLASS 12.0	27-37-16-92		

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E223759

**Data sheet****RIM 3 6/24VUC GN**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

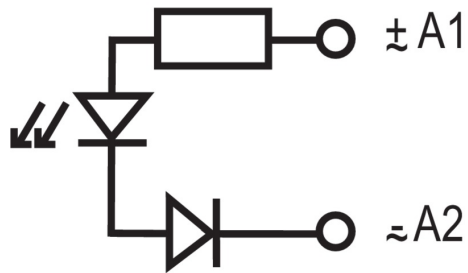
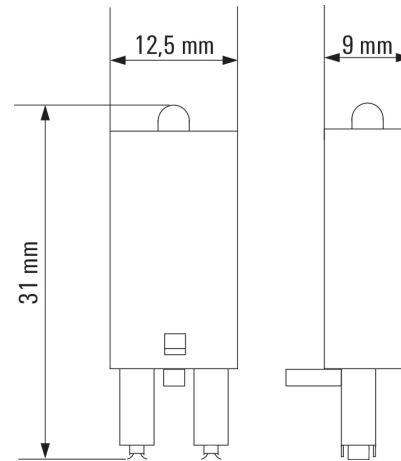
**Technical data****Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">EPLAN, WSCAD</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

**RIM 3 6/24VUC GN**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings****Wiring diagram****Dimensional drawing**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[8713750000](#)