


PXEB5410MM5055 Datasheet

Product Name // 4 Channel Jam Nut Bulkhead Connector with Cable Retention

 [View Product Page](#)

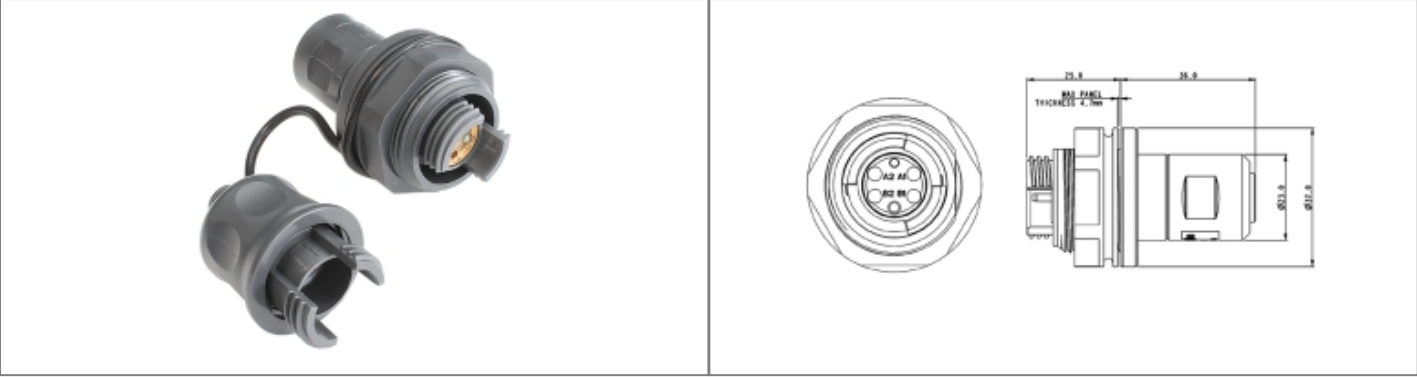

// Product Description:

- Non-terminated Jam Nut Bulkhead Connector for a 4-Channel Multimode Cable with 5-5.5mm Diameter
 - Designed to MIL-DTL83526D
 - Compatible with any connector that follows MIL-DTL83526D
 - Compatible with OM1 & OM3
- Dust Cap, Lanyard, and Ferrules (termini) for the Cable Included
 - Mates with Plug Connectors (hermaphroditic)
 - Operating Temperature -50°C to +80°C
 - Available in 2 Channel

// General Information:

Product Display Title:	4 Channel Jam Nut Bulkhead Connector with Cable Retention
Product Family:	Circular Fiber Connectors
Product Series:	5000 Series Expanded Beam
Max Insertion Loss:	<2dB
Avg Insertion Loss:	<1.5dB
Body Colour:	Dark Grey
Body Material:	Polycarbonate/Polybutylene Terephthalate (PC/PBT)
Body Material Type:	Plastic Body
Contact Type:	Expanded Beam
Coupling Nut Retention Force:	1Nm
Coupling Type:	Screw
Diameter Over Coupling Ring Mm:	30mm
Fibre Mode:	MM
Flamability Rating:	UL94V-0
Function:	EB Jam Nut Bulkhead Connector
Ip Rating:	IP68
Material Finish:	Matt
Max Cable Entry Size:	5.5mm
Min Cable Entry Size:	5mm
Max Operating Temperature:	+80°C
Min Operating Temperature:	-50°C
Max Panel Thickness:	4.7mm
Rohs Compliant:	Yes

// Product PDF Links

 [5000 Series Expanded Beam Product...](#)

// Product 3D CAD Model Links

 [PXEB5410MM50553D CAD Model](#)