

D38999/21 Box Mount Hermetic Receptacle MIL-DTL-38999 Series III

How To Order: MS

Basic Specification
D38999

Connector Material / Finish
N - CRES, Nickel
Y - CRES, Passivated

Insert Arrangement
Per MIL-STD-1560;
See Pages B2 - B4

Alternate Key Position
A, B, C, D, E
(N = Normal)

D38999

/21

Y

B

35

P

N



Shell Style
/21 - Box Mount

Shell Size

A - 9 F - 19
B - 11 G - 21
C - 13 H - 23
D - 15 J - 25
E - 17

Contact Termination

P - Pin, Solder Cup S - Socket, Solder Cup
X - Pin, Eyelet Z - Socket, Eyelet
C - Pin, PCB D - Socket, PCB
Flex Feedthrough Flex Feedthrough

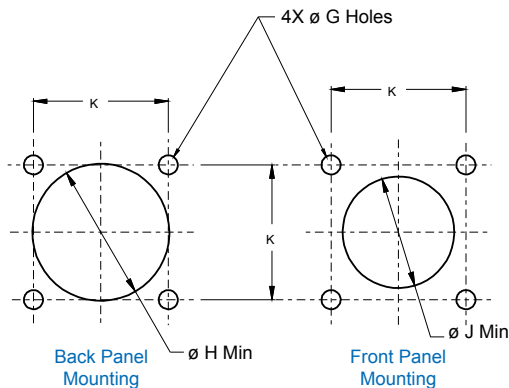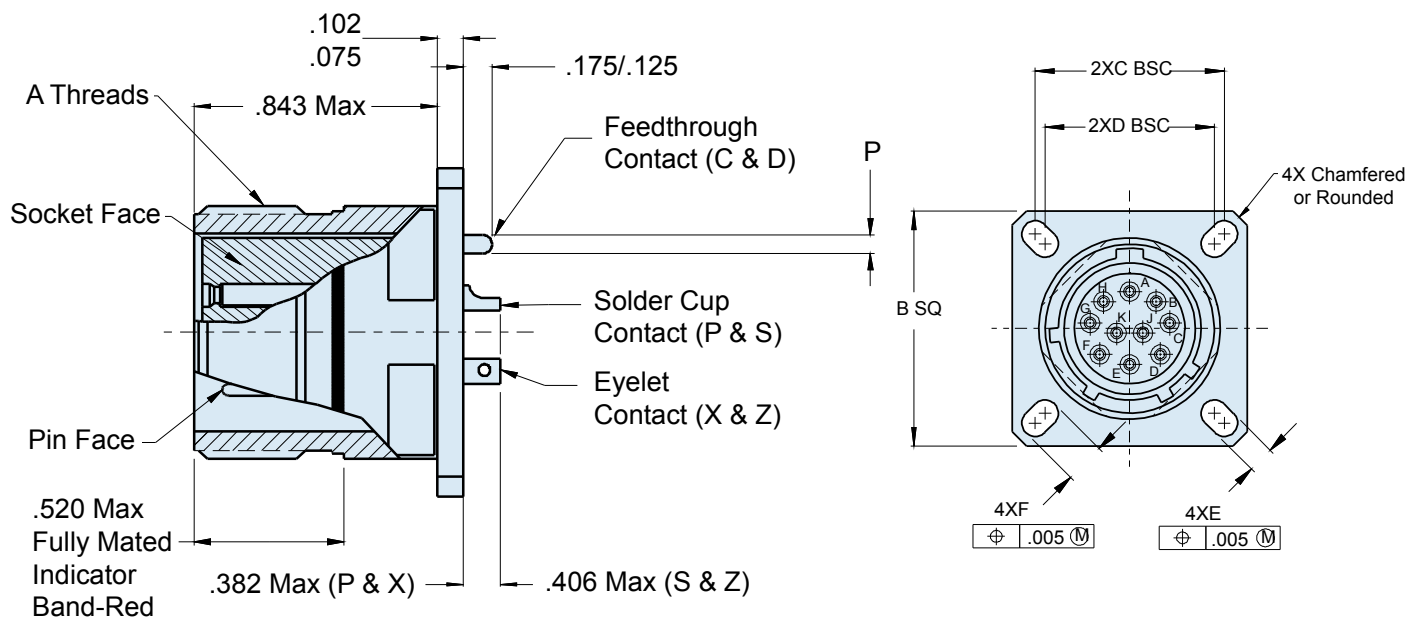

D38999/21


Box Mount Hermetic Receptacle

MIL-DTL-38999 Series III



D38999 QPL
Hermetics

How To Order: Commercial

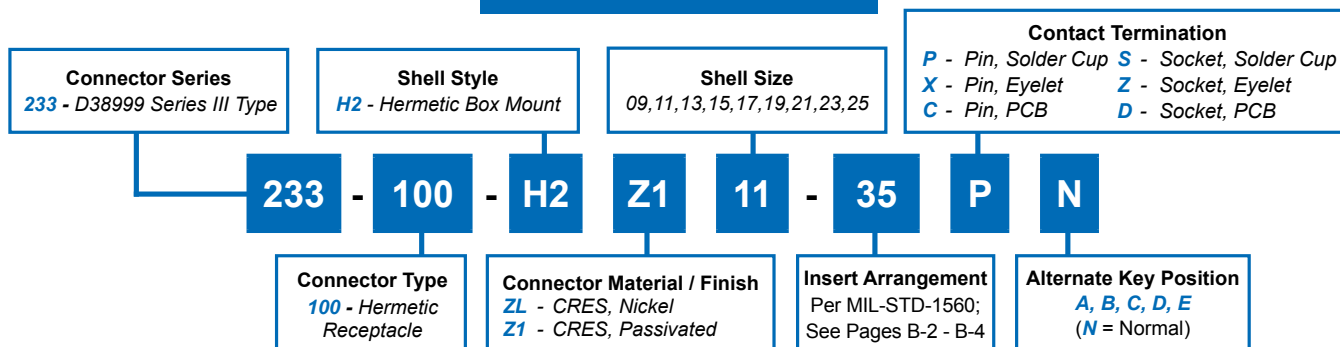

B

TABLE I: CONNECTOR DIMENSIONS

SHELL SIZE CODE	SHELL SIZE	A THREAD	B SQ ±.012(0.3)	C BSC	D BSC	E ±.008(0.2)	F ±.008(0.2)
A	9/09	.6250-.1P-.3L-TS-2A	.937(23.8)	.719(18.3)	.594(15.1)	.128(3.3)	.216(5.5)
B	11	.7500-.1P-.3L-TS-2A	1.031(26.2)	.812(20.6)	.719(18.3)	.128(3.3)	.194(4.9)
C	13	.8750-.1P-.3L-TS-2A	1.126(28.6)	.906(23.0)	.812(20.6)	.128(3.3)	.194(4.9)
D	15	1.0000-.1P-.3L-TS-2A	1.220(31.0)	.969(24.6)	.906(23.0)	.128(3.3)	.194(4.9)
E	17	1.1875-.1P-.3L-TS-2A	1.311(33.3)	1.062(27.0)	.969(24.6)	.128(3.3)	.194(4.9)
F	19	1.2500-.1P-.3L-TS-2A	1.437(36.5)	1.156(29.4)	1.062(27.0)	.128(3.3)	.194(4.9)
G	21	1.3750-.1P-.3L-TS-2A	1.563(39.7)	1.250(31.8)	1.156(29.4)	.128(3.3)	.194(4.9)
H	23	1.5000-.1P-.3L-TS-2A	1.689(42.9)	1.375(34.9)	1.250(31.8)	.154(3.9)	.242(6.1)
J	25	1.6250-.1P-.3L-TS-2A	1.811(46.0)	1.500(38.1)	1.375(34.9)	.154(3.9)	.242(6.1)

TABLE I (CONTINUED): CONNECTOR DIMENSIONS

SHELL SIZE CODE	SHELL SIZE	Ø G HOLES ±.005(0.1)	Ø H MIN	Ø J MIN	K ±.005(0.1)
A	9/09	.128(3.3)	.656(16.7)	.516(13.1)	.719(18.3)
B	11	.128(3.3)	.781(19.8)	.625(15.9)	.812(20.6)
C	13	.128(3.3)	.921(23.4)	.750(19.1)	.906(23.0)
D	15	.128(3.3)	1.047(26.6)	.906(23.0)	.968(24.6)
E	17	.128(3.3)	1.218(30.9)	1.016(25.8)	1.062(27.0)
F	19	.128(3.3)	1.296(32.9)	1.142(35.9)	1.156(29.4)
G	21	.128(3.3)	1.421(36.1)	1.266(32.2)	1.250(31.8)
H	23	.154(3.9)	1.546(39.3)	1.375(34.9)	1.375(34.9)
J	25	.154(3.9)	1.672(42.5)	1.484(37.7)	1.500(38.1)

TABLE II: CONTACT SIZE

PRINTED CIRCUIT TAIL CONFIGURATIONS
CONTACT STYLE C AND D



SIZE 12 AND SIZE 16

.050 ± .015
(1.27 ± 0.38)

SIZE 22D AND SIZE 20

Contact Size	Ø P
22D	.011 (0.28) .015 (0.38)
20	.024 (0.61) .028 (0.71)
16	.0635 (1.61) .0615 (1.56)
12	.095 (2.41) .093 (2.36)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[D38999/21NA35PB](#) [D38999/21NA35PC](#) [D38999/21NB35PA](#) [D38999/21NC35PB](#) [D38999/21YA35XN](#)
[D38999/21YB35PB](#) [D38999/21YB5CN](#) [D38999/21YB98XA](#) [D38999/21YB98XB](#) [D38999/21YC35PB](#)
[D38999/21YC35PC](#) [D38999/21YC35PE](#) [D38999/21YD19PA](#) [D38999/21YD35PN](#) [D38999/21YD97PA](#)
[D38999/21YE35PA](#) [D38999/21YE35PN](#) [D38999/21YE6PA](#) [D38999/21YE8PN](#) [D38999/21YE99PN](#)
[D38999/21YF35PA](#) [D38999/21YG35SN](#) [D38999/21YG41PA](#) [D38999/21YG41PN](#) [D38999/21YG41SN](#)
[D38999/21YH21PN](#) [D38999/21YH53PN](#) [D38999/21YH55SN](#) [D38999/21YJ19PN](#) [D38999/21YJ4PN](#)
[D38999/21YC4SN](#) [D38999/21NE8PN](#) [233-100-H2Z111-35PB](#) [233-100-H2Z111-98PA](#) [233-100-H2Z111-98PB](#) [233-100-H2Z111-98PC](#) [233-100-H2Z111-98PN](#) [233-100-H2Z113-35PB](#) [233-100-H2Z113-35PC](#) [233-100-H2Z113-35PE](#)
[233-100-H2Z113-98PA](#) [233-100-H2Z113-98PB](#) [233-100-H2Z113-98PN](#) [233-100-H2Z115-18PN](#) [233-100-H2Z115-19PA](#) [233-100-H2Z115-19PN](#) [233-100-H2Z117-26PB](#) [233-100-H2Z117-35PN](#) [233-100-H2Z117-99PN](#) [233-100-H2Z119-32PN](#) [233-100-H2Z119-35PA](#) [233-100-H2Z121-41PA](#) [233-100-H2Z121-41PN](#) [233-100-H2Z123-21PA](#) [233-100-H2Z123-21PN](#) [233-100-H2Z125-35PN](#) [233-100-H2ZL11-35PB](#) [233-100-H2ZL11-35PN](#) [233-100-H2ZL11-98PN](#) [233-100-H2ZL11-99PC](#) [233-100-H2ZL11-99PN](#) [233-100-H2ZL13-35PA](#) [233-100-H2ZL13-35PB](#) [233-100-H2ZL15-19PN](#) [233-100-H2ZL15-35PN](#) [233-100-H2ZL15-97PN](#) [233-100-H2ZL17-26PN](#) [233-100-H2ZL21-11PN](#) [233-100-H2ZL21-16PN](#) [233-100-H2ZL23-35PN](#) [233-100-H2ZL25-19PA](#) [233-100-H2ZL25-19PB](#) [D38999/21YE26PB](#) [D38999/21NA98CC](#)
[D38999/21NB2PN](#) [D38999/21NB35PB](#) [D38999/21NB35PC](#) [D38999/21NB4XN](#) [D38999/21NB5PA](#)
[D38999/21NB99PB](#) [D38999/21NB99PC](#) [D38999/21NB99PN](#) [D38999/21NC35PA](#) [D38999/21NC4PN](#)
[D38999/21NC8CB](#) [D38999/21NC8PN](#) [D38999/21NC98SA](#) [D38999/21ND19PN](#) [D38999/21ND35PA](#)
[D38999/21NE26PB](#) [D38999/21NE26PN](#) [D38999/21NE35PN](#) [D38999/21NE6PN](#) [D38999/21NF32PN](#)
[D38999/21NF35CC](#) [D38999/21NF35PA](#) [D38999/21NF35PN](#) [D38999/21NG16PN](#) [D38999/21NG35CN](#)
[D38999/21NG35PN](#) [D38999/21NH35PN](#)