

*Image for illustrative purpose only*

Summary

[Request a quote](#)[Catalog](#)

Number of contacts Low Voltage	6
Wire Size/AWG	32 - 28
Gender	Reverse Gender
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	1.00 - 8.30 mm
Size	0T
Series	T - Small Outdoor keyed

Technical details

Electrical Configuration

Contact Termination Low voltage	Crimp
R (max)	8.7 mOhm
Insert configuration value	0T.306 - 6 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	2.5 A
Vtest (contact-contact)	1400 V (AC), 1980 V (DC)
Vtest (contact-shell)	1200 V (AC), 1700 V (DC)
Contact retention	12 N
Contact Type	Crimp
Max. Conductor	0.09 mm ² (AWG 28)
Min. Conductor	0.035 mm ² (AWG 32)
Bucket Dia.	0.45 mm (0.018in)
Contact Dia.	0.5 mm (0.02in)
Number of contacts Low Voltage	6
Wire Size/AWG	32 - 28
Gender	Reverse Gender

Form & Material

Shell style / Model id	EE - Fixed receptacle, nut fixing, back panel mounting
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	2 keys (gamma=80, plug: female contacts, receptacle: male contacts)
Colour	Grey
Weight	5.07 g


Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	>3000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [6 ms]
Salt Spray Corrosion	>1000 hr

Cable fixation

Jacket cable outside diameter [mm]	1.00 - 8.30 mm
------------------------------------	----------------

Drawings

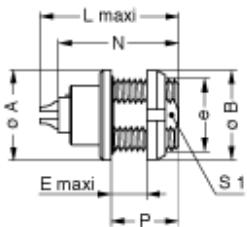

Dimensions

	A	B	e	E	Lmax	Nmax	S1	P
mm.	12	12	M9x0.6	6.5	21	19.1	8.2	9
in.	0.47	0.47			0.26	0.83	0.32	0.35

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/eel-0t-306-cyc.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories

Replacement contact	FGG.0B.554.ZZC
Compatible cap	BRE.0T.200.CAZ

Tools

Positionner	DCE.91.050.BVC
Extraction tool	DCC.05.02B.LAG
Crimp tool	DPC.91.701.V
Spanner wrench	Socket for torque wrench DCM.0S.M09.4

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.06.T28.031PGCE	PVC	GREY	
CMN.06.T28.031PGZE		grey	
CMN.06.T28.031PNCE	PVC	Black	
CMN.06.T28.031PNZE			
CMN.06.T28.042QBCE	TPR (medical)		
CMN.06.T28.044PGZE		grey	
CMN.06.T28.044PNZE			
12080	PVC	Grey	
6280	PVC	Black	

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/eel-0t-306-cyc.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.