


PAGE 1/1	ISSUE 03-06-13	SERIES LC	PART NUMBER F727710700
----------	----------------	-----------	------------------------

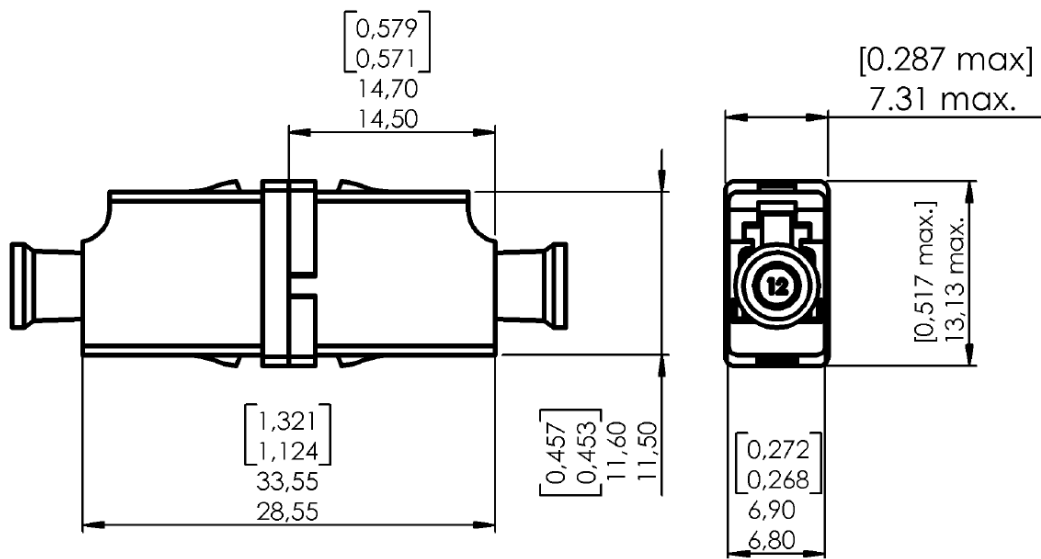

Dimensions: mm [inches]

GENERAL

Type: IEC 61754-20 (LC)  
RJ-45 latching system

Mounting: Snap in mounting  
Max. panel thickness 1.7mm

Alignment Sleeve: Zirconia

Color: BEIGE

CHARACTERISTICS (Dependent on cable or fiber construction)

Material: Plastic molded: Material in accordance with  
TELCORDIA GR-326 CORE  
Inflammability V0 (UL 94)

Mechanical: Endurance: 200 matings

Plug Retention: 68N

Environmental: Storage temperature range: -40°C / +85°C  
Operating temperature range: -40°C / +70°C

Proof Test : Straight pull: 68N  
Side pull: 23N

Vibration Test : 10 to 55Hz, 1.5mm (peak to peak), 2Hr/axis

(Performance and specification: see document GEN\_F727 001)