

Receptacle for rear panel mounting


General information

Part number	GKCWAM-P07UB00-000L
Termination	PCB
Size	00
Locking principle	Break-Away
Coding	A (light brown)
Cable Diameter	3.2 – 5.0 mm




Illustrations may differ from original product.
Dimensions, unless otherwise specified, in mm.


CODING:A

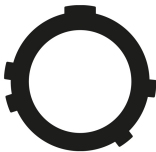

POSITIONS: 7 positions

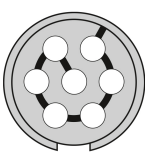

PANEL CUT OUT:

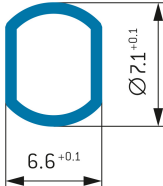

DIMENSIONS:

Mechanical and environmental data

Degree of protection*	IP6K8 / IP6K9K
Operating temperature	-51 °C – 125 °C
Mating cycles	5000

*mated condition

Material and surface treatments

Housing	Cu-alloy with ruthenium finish
Contact	Cu-alloy with gold finish

All shown connectors are defined without breaking capacity (COC) according to IEC 61984:2008 (VDE 0627:2009).

ODU MEDI-SNAP® and MINI-SNAP® are UL-approved (E110586).

ODU reserves the right to make changes based on the current state of knowledge without prior notice without being obliged to provide replacement deliveries or refinements of older designs.