
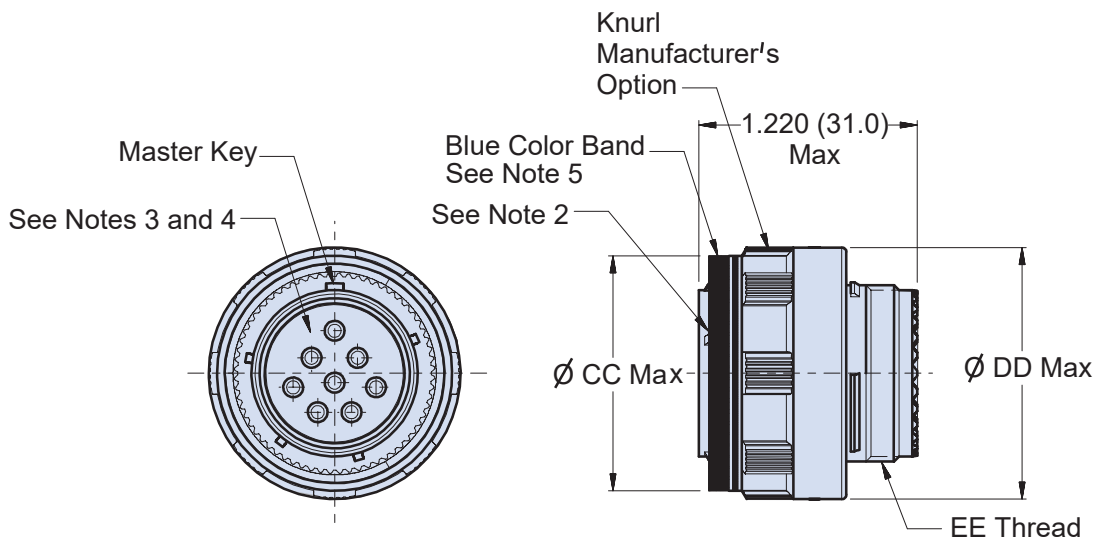


233-105-G6 MIL-DTL-38999 Series III Type Environmental Plug Connector

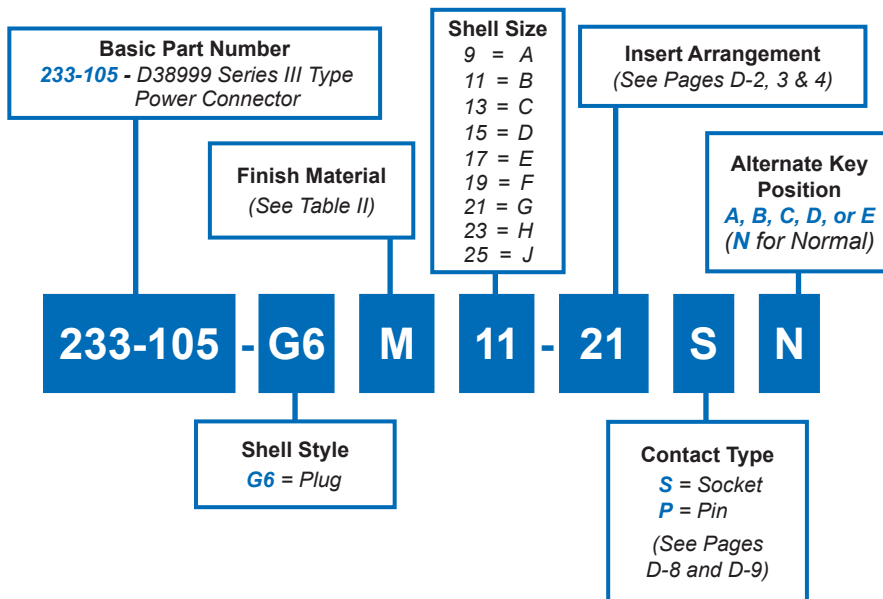

Consult factory for available insert arrangements.

APPLICATION NOTES

1. Material/ Finishes:
Barrel, Coupling Nut - See Table II
(Composite Coupling Nut - No Plating Required).
Insulators- High Grade Rigid Dielectric/ N.A
Seals- Fluorosilicone/ N.A.
2. Assembly to be identified with Glenair's name, part number and date code space permitting.
3. Insert arrangement in accordance with MIL-STD-1560.
4. Insert arrangement shown is for reference only.
5. Blue Color Band indicates rear release retention system.
7. Metric Dimensions (mm) are indicated in parentheses.

233-105-G6
MIL-DTL-38999 Series III Type
Environmental Plug Connector



TABLE II: FINISH			
SYM	MATERIAL	FINISH	MIL SYM
ME	Aluminum	Electroless Nickel	F
NF		Cadmium O.D. Over Electroless Nickel	W
ZN		Zinc Ni, Olive Drab	Z
ZE		Zinc Ni, No Chromate	
ZR		Zinc Ni, Black (Tri-Valent CR)	
AL		Pure-Dense Electro-Deposited Aluminum	P
MT		Ni-PTFE 1000 Hour Grey™	T
XM	Composite	Electroless Nickel	M
XMT		Ni-PTFE 1000 Hour Grey™	
XO		No Finish	
XW		Cadmium O.D. over Electroless Nickel	J
Z1	Stainless Steel	Passivate	
ZC		Zinc Colbalt	
ZL		Electro-Deposited Nickel	
ZW		Cadmium O.D. over Nickel	
AB	Marine Bronze	None (Clean Only)	

*Consult Factory for Additional Plating Options

TABLE III: SHELL SIZE				
Shell Size Code	Shell Size	CC Max Dia	DD Max Dia	EE Thread
A	09	.811 (20.6)	.858 (21.8)	M12 x 1.0-6g 0.100R
B	11	.929 (23.6)	.984 (25.0)	M15 x 1.0-6g 0.100R
C	13	1.110 (28.2)	1.157 (29.4)	M18 x 1.0-6g 0.100R
D	15	1.232 (31.3)	1.280 (32.5)	M22 x 1.0-6g 0.100R
E	17	1.358 (34.5)	1.406 (35.7)	M25 x 1.0-6g 0.100R
F	19	1.469 (37.3)	1.516 (38.5)	M28 x 1.0-6g 0.100R
G	21	1.594 (40.5)	1.642 (41.7)	M31 x 1.0-6g 0.100R
H	23	1.720 (43.7)	1.768 (44.9)	M34 x 1.0-6g 0.100R
J	25	1.843 (46.8)	1.890 (48.0)	M37 x 1.0-6g 0.100R

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[233-105-G6ZR17-35SN](#) [233-105-G6ZR21-35SN](#) [233-105-G6ZR15-35SN](#) [233-105-G6ZR19-35SN](#) [233-105-G6ZR19-35SA](#) [233-105-G6MT17-06PN](#) [233-105-G6MT17-06PA](#) [233-105-G6ZR1304SN](#) [233-105-G6MT25-29PA](#) [233-105-07MT17-08PN](#) [233-105-G6MT17-26SA](#) [233-105-G6MT17-26SB](#) [233-105-g6me15-35pn](#) [233-105-05ME15-35SN](#) [233-105-G6M25-35SN](#) [233-105-G6MT17-06SN](#) [233-105-G6AB11-5SN](#) [233-105-G6AB19-32PA](#) [233-105-G6MT17-35SB](#) [233-105-G6Z121-35PN](#) [233-105-G6ZR21-75SN](#) [233-105-G6M15-35SN](#) [233-105-G6M19-35SN](#) [233-105-G6M15-97SN](#) [233-105-G6ZR13-04SN](#) [233-105-G6NF11-35SN](#) [233-105-20ME15-55PN](#) [233-105BG6XM15-18SN](#) [233-105BG6Z109-98SN](#) [233-105BG6Z115-19SA](#) [233-105BG6Z115-19SN](#) [233-105-26ME15-35SN](#) [233-105-00M13L-26SN](#) [233-105-26MT23-23SN](#) [233-105-G6M13L-26PN](#) [233-105-G6MT13-98PN](#) [233-105-G6MT25-35SB](#) [233-105-G6ZR25-35PB](#) [233-105-00MT17-26PA](#) [233-105-00NF15-35SN](#) [233-105-00NF19-11PN](#) [233-105-00NF23L-54SN](#) [233-105-00Z111-35PN](#) [233-105-00Z121-35SB](#) [233-105-05M17-35PN](#) [233-105-05M17-35SN](#) [233-105-05NF15-18SN](#) [233-105-05NF17-26PN](#) [233-105-05Z119-32PC](#) [233-105-05Z123-55SN](#) [233-105BG6XM15-18SA](#) [233-105-D0MT21-11AN](#) [233-105-G6AB17-35PN](#) [233-105-G6AB17-35SN](#) [233-105-G6AB21-41PN](#) [233-105-G6M09-35SN](#) [233-105-G6M15-35PN](#) [233-105-G6M17-06SN](#) [233-105-G6M17-26PN](#) [233-105-G6M21-35HN](#) [233-105-G6ME15-35SN](#) [233-105-G6ME17-35PN](#) [233-105-G6ME25-35PU](#) [233-105-G6ME25-35SU](#) [233-105-G6MT09-35SN](#) [233-105-G6MT15-05SN](#) [233-105-G6MT15-35PN](#) [233-105-G6MT17-08PB](#) [233-105-G6MT17-35SA](#) [233-105-G6MT19-35PN](#) [233-105-G6MT19L-4BN](#) [233-105-G6MT21-16SN](#) [233-105-G6MT21-39SB](#) [233-105-G6MT23-35PA](#) [233-105-G6MT25-43SN](#) [233-105-G6NF15-35SA](#) [233-105-G6NF17-06AN](#) [233-105-G6NF17-35SA](#) [233-105-G6NF21-35SN](#) [233-105-G6NF23L-54PN](#) [233-105-G6Z111-35SN](#) [233-105-G6Z111-98SD](#) [233-105-G6Z113-35SN](#) [233-105-G6Z115-97SN](#) [233-105-G6Z117-99SN](#) [233-105-G6Z119-35PB](#) [233-105-G6Z123-53SN](#) [233-105-G6ZR13-35SN](#) [233-105-G6ZR15-35SU](#) [233-105-G6ZR17-35SA](#) [233-105-G6ZR17L-75PA](#) [233-105-G6ZR17L-75SA](#) [233-105-G6ZR25-35PN](#) [233-105-G6ME11-35SA](#) [233-105-G6ME11-98SN](#) [233-105-G6AB17-26SA](#) [233-105-G6M17-35PN](#) [233-105-G6M25-35PN](#) [233-105-G6ME23L-54PA](#) [233-105-G6ME23L-54SA](#)