


JT06R (MS27473) — crimp straight plug

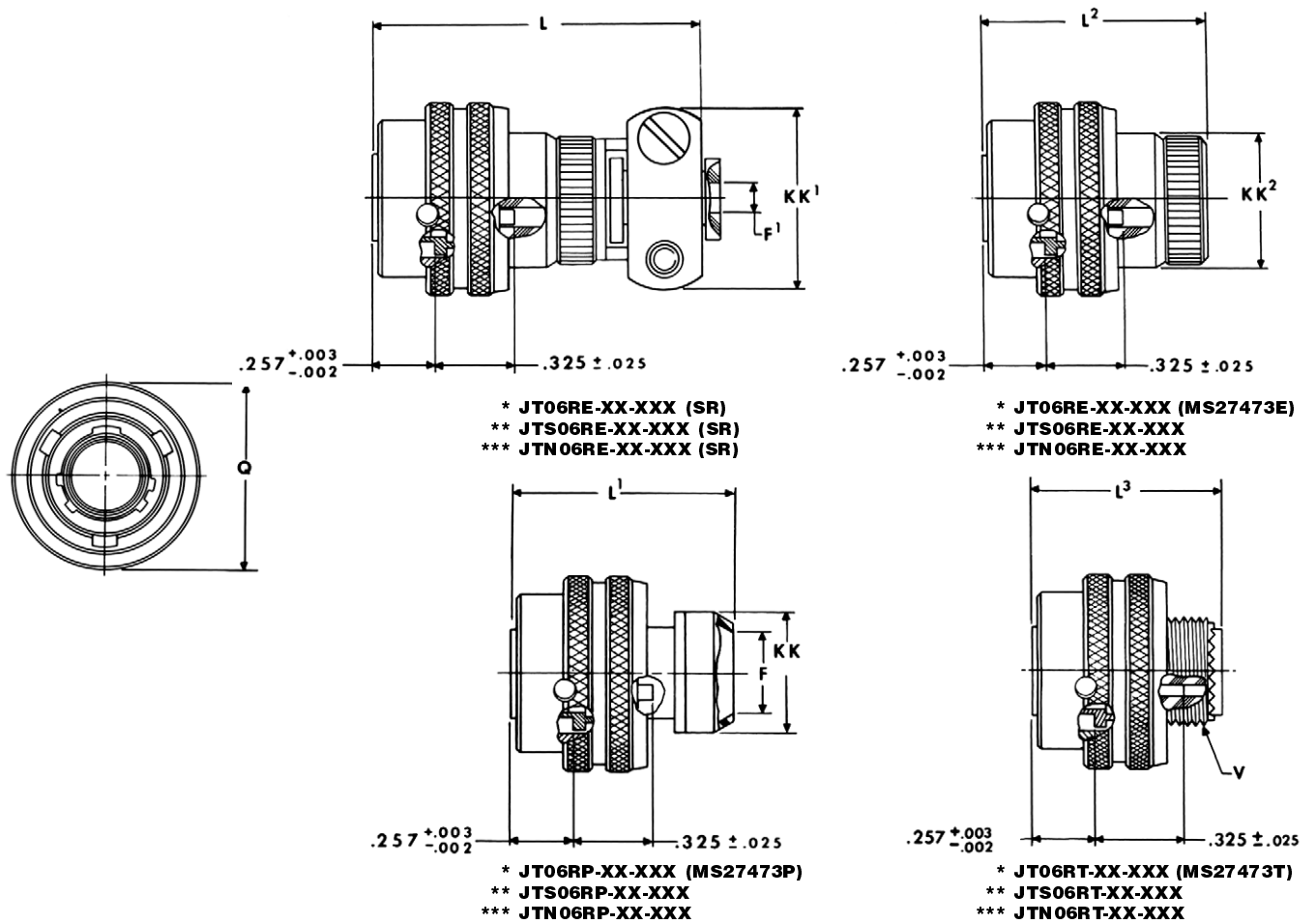

* To complete order number see page 49.

** High temperature version; to complete order number see page 49.

*** Clear iridite finish (gold color), N₂O₄ resistant; to complete order number see page 49.

Shell Size	F Dia.	F ¹ Dia. +.010 -.025	L Max.	L ¹ Max.	L ² Max.	L ³ Max.	Q Dia. Max.	V Thread Modified		KK Dia. Max.	KK ¹ Max.	KK ² Dia. Max.
								Class 2A UNEF	Modified Major Dia.			
8	.444	.125	1.562	1.000	.938	.891	.734	.4375-28	.421 - .417	.625	.812	.578
10	.558	.188	1.562	1.000	.938	.891	.844	.5625-24	.542 - .538	.750	.875	.703
12	.683	.312	1.562	1.000	.938	.891	1.016	.6875-24	.667 - .663	.875	1.000	.828
14	.808	.375	1.812	1.000	.938	.891	1.141	.8125-20	.791 - .787	1.000	1.125	.953
16	.909	.500	1.812	1.000	.938	.891	1.265	.9375-20	.916 - .912	1.125	1.188	1.078
18	1.034	.625	1.812	1.000	.938	.891	1.391	1.0625-18	1.034 - 1.030	1.250	1.438	1.203
20	1.159	.625	1.812	1.000	.938	.891	1.500	1.1875-18	1.158 - 1.154	1.375	1.438	1.328
22	1.284	.750	1.938	1.000	.938	.891	1.625	1.3125-18	1.283 - 1.279	1.500	1.625	1.453
24	1.409	.800	1.938	1.062	.938	.891	1.750	1.4375-18	1.408 - 1.404	1.625	1.719	1.578

All dimensions for reference only.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

[MS27473E18F28S](#) [MS27473E10F35P](#) [MS27473E16F26P](#) [MS27473E16F26PA](#) [MS27473E16F26S](#)
[MS27473E16F26SA](#) [MS27473E16F35P](#) [MS27473E16F35PA](#) [MS27473E16F35PD](#) [MS27473E16F35S](#)
[MS27473E16F42S](#) [MS27473E16F99P](#) [MS27473E16F99S](#) [MS27473E18F32P](#) [MS27473E18F32PA](#)
[MS27473E18F35S](#) [MS27473E18F35SA](#) [MS27473E20F16S](#) [MS27473E20F35P](#) [MS27473E20F35PA](#)
[MS27473E20F35S](#) [MS27473E20F39P](#) [MS27473E20F39PA](#) [MS27473E20F41P](#) [MS27473E20F41PA](#)
[MS27473E20F41S](#) [MS27473E20F41SA](#) [MS27473E18F11S](#) [MS27473E16F42P](#) [MS27473E18F96P](#)
[MS27473E16F35SC](#) [MS27473E16F99SA](#) [MS27473E16F99SC](#) [MS27473E18F11P](#) [MS27473E16F8SC](#)
[MS27473E16F8PC](#) [MS27473E18F11SC](#) [MS27473E16F8SB](#) [MS27473E18F35SD](#) [MS27473E20F16PA](#)
[MS27473E18F96S](#) [MS27473E16F42PD](#) [MS27473E16F35SD](#) [MS27473E20F16P](#) [MS27473E16F35SB](#)
[MS27473E20F35SA](#) [MS27473E18F11PB](#) [MS27473E20F16SA](#) [MS27473E20F35SD](#) [MS27473E18F35PD](#)
[MS27473E18F11SB](#) [MS27473E18F96SB](#) [MS27473E20F35PC](#) [MS27473E18F35SB](#) [MS27473E18F32PB](#)