



Miniature Cylindrical MIL-C-26482, Series 2 MS3476 straight plug MS3475 straight plug with RFI grounding fingers

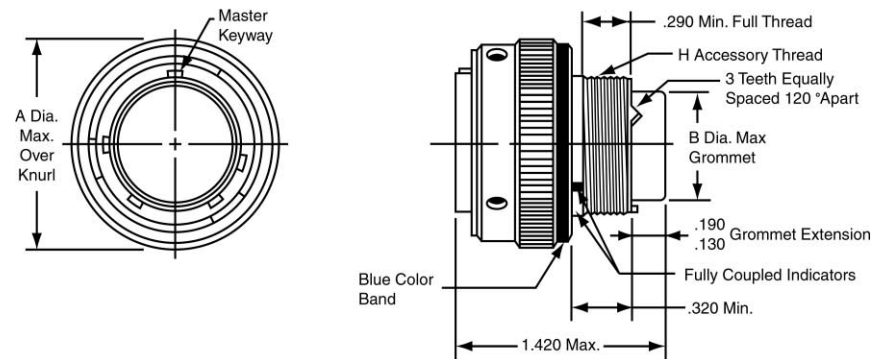

**Plug Shell,
Bayonet Coupling**

Military No. MS3476
Amphenol/Matrix No. MB16

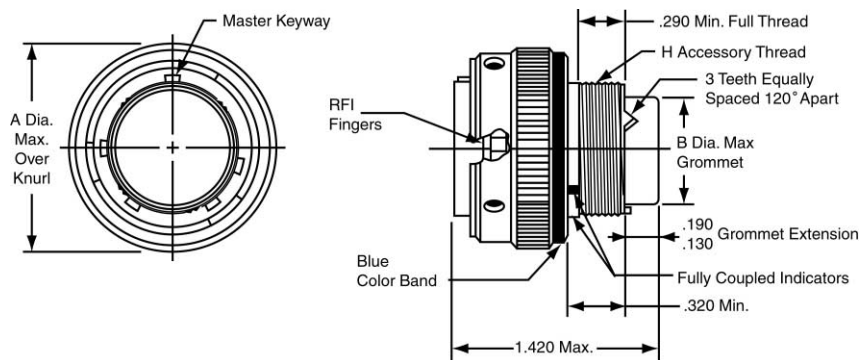

**Plug Shell, RFI Grounding,
Bayonet Coupling**

Military No. MS3475
Amphenol/Matrix No. MB18

To complete order number see how to order, page 14.

Shell Size	A Dia. Max.	B Dia. Max.	H Accessory Thread Class 2A
8	.782	.305	.5000-20 UNF
10	.926	.405	.6250-24 UNEF
12	1.043	.531	.7500-20 UNEF
14	1.183	.665	.8750-20 UNEF
16	1.305	.790	1.0000-20 UNEF
18	1.391	.869	1.0625-18 UNEF
20	1.531	.994	1.1875-18 UNEF
22	1.656	1.119	1.3125-18 UNEF
24	1.777	1.244	1.4375-18 UNEF

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

[MS3475L10-6P](#) [MS3475L10-6PW](#) [MS3475L10-6S](#) [MS3475L10-6SW](#) [MS3475L12-10P](#) [MS3475L12-10PW](#)
[MS3475L12-10S](#) [MS3475L12-10S-LC](#) [MS3475L12-10SW](#) [MS3475L12-10SW-LC](#) [MS3475L12-3S](#) [MS3475L12-8SW](#)
[MS3475L12-8SW-LC](#) [MS3475L14-12P](#) [MS3475L14-12PW](#) [MS3475L14-15P](#) [MS3475L14-15S](#) [MS3475L14-18P](#)
[MS3475L14-18S](#) [MS3475L14-19P](#) [MS3475L14-19PW](#) [MS3475L14-19S](#) [MS3475L14-19SW](#) [MS3475L14-19SX](#)
[MS3475L14-19SY](#) [MS3475L14-4S](#) [MS3475L14-5P](#) [MS3475L14-5S](#) [MS3475L16-26P](#) [MS3475L16-26PW](#)
[MS3475L16-26S](#) [MS3475L16-26SW](#) [MS3475L16-8S](#) [MS3475L18-11SW](#) [MS3475L18-32P](#) [MS3475L18-32PW](#)
[MS3475L18-32PX](#) [MS3475L18-32S](#) [MS3475L18-8P](#) [MS3475L18-8S](#) [MS3475L20-16P](#) [MS3475L20-16S](#)
[MS3475L20-24S](#) [MS3475L20-39P](#) [MS3475L20-41S](#) [MS3475L20-41S-LC](#) [MS3475L20-41SW](#) [MS3475L20-41SX](#)
[MS3475L22-21P](#) [MS3475L22-21PX](#) [MS3475L22-41S](#) [MS3475L22-55P](#) [MS3475L22-55PW](#) [MS3475L22-55PX](#)
[MS3475L22-55S](#) [MS3475L22-55SX](#) [MS3475L24-31P](#) [MS3475L24-31S](#) [MS3475L24-61P](#) [MS3475L24-61PW](#)
[MS3475L24-61PX](#) [MS3475L24-61S](#) [MS3475L24-61SW](#) [MS3475L24-61SZ](#) [MS3475L8-98S](#) [MS3475W10-6P](#)
[MS3475W10-6P-LC](#) [MS3475W10-6S](#) [MS3475W10-6SW](#) [MS3475W12-10P](#) [MS3475W12-10PW](#) [MS3475W12-10S](#)
[MS3475W12-10S-LC](#) [MS3475W12-10SW](#) [MS3475W12-10SX](#) [MS3475W12-10SY](#) [MS3475W12-3P](#) [MS3475W12-3S](#)
[MS3475W12-8P](#) [MS3475W12-8S](#) [MS3475W14-12S](#) [MS3475W14-15P](#) [MS3475W14-15PW](#) [MS3475W14-15S](#)
[MS3475W14-18S](#) [MS3475W14-19P](#) [MS3475W14-19PW](#) [MS3475W14-19PX](#) [MS3475W14-19S](#) [MS3475W14-19SW](#)
[MS3475W14-5P](#) [MS3475W14-5S](#) [MS3475W14-5S-LC](#) [MS3475W14-9S](#) [MS3475W16-26P](#) [MS3475W16-26S](#)
[MS3475W16-26S-LC](#) [MS3475W16-26SW](#) [MS3475W16-8P](#) [MS3475W16-8S](#)