

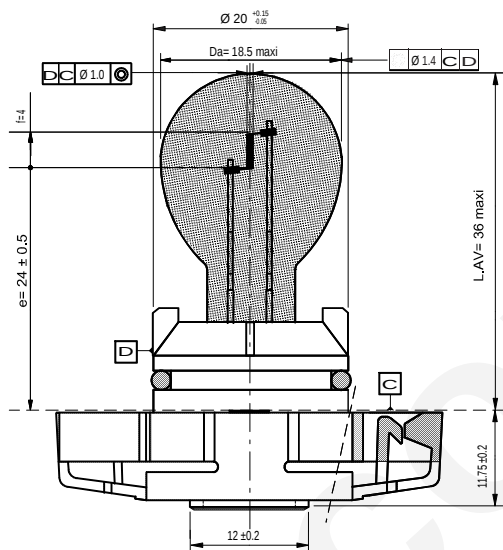


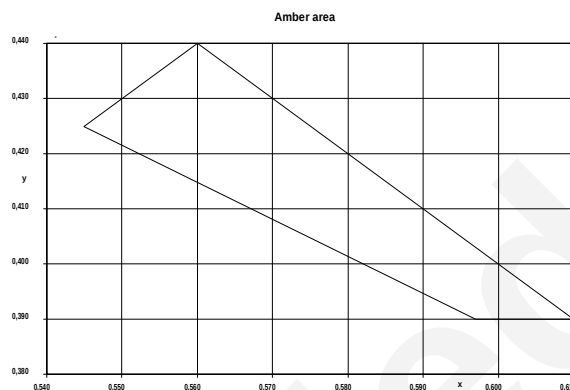

HiPer E18 PSY19W 12V PG20/2 NA

12275

Date : 09/12/2007

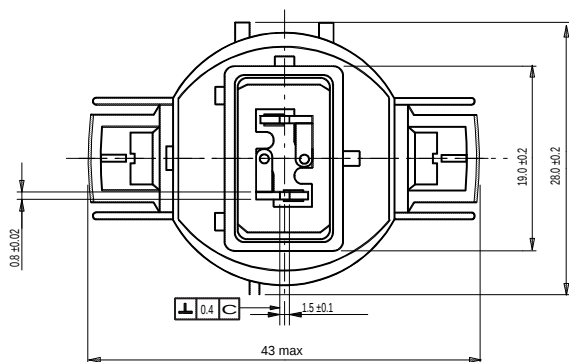

****BULB NOT MANUFACTURED BY CFC INDUSTRIES****

Dimensions in mm

Turn signal	
PSY19W 12V	
Cap : PG20/2	IEC 61-1 / 7004-127-
Type : 12275	
Code Nr : 9246 537 171	
ECE R37	E4 2ME
C-8Z	Straight-axial -"Z" shape
Made in France, Chartres	

Product specifications are subject to modification without prior notice

Colour	
Required area	ECE R37
Photometric values	
Photometry voltage	13,5V DC
Power	19,00 W ±5,2%
Luminous flux	215,0 lm +20%
Mechanical values	
Mechanical bulb resistance	40,0 N min.
Reliability	
Life test voltage	13,5V DC
Life test cycle	90/min - 50% - 15"ON/15"OFF (Blinking)
Lumen maintenance at	1 200 h
Lumen maintenance	70,0 % min.
Colour maintenance at	1 200 h
Life : Tc	2 400 h
Life : B3	1 200 h
Resistance to environment	
Humidity resistance, FAKRA	
Maximum permissible bulb temperature	350 °C MAX

CEC INDUSTRIES LTD

599 Bond St, Lincolnshire, IL 60069