



Series
EPXB

SIZE 2 PLUG CONNECTOR
WITH A, B, C, D, E & F PIN POLARIZATION GUIDE

Issue:
Sept 27, 2011

Page
1/1

2 self locking threads
for 4-40 UNC 2A screws
For rear panel mounting only
coupling torque: $1,2 \pm 0,10$ N.m
screw head max $\phi 6$ [.236]

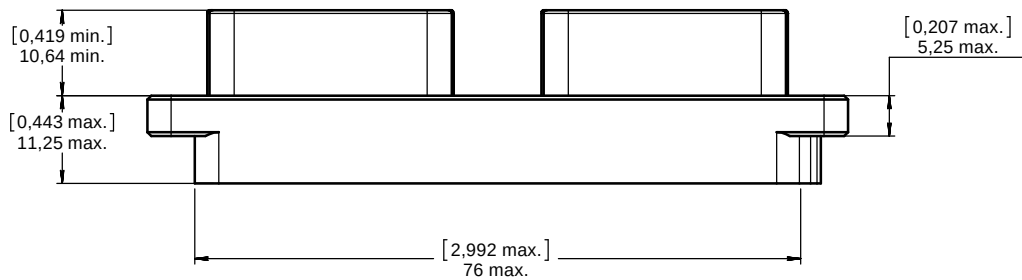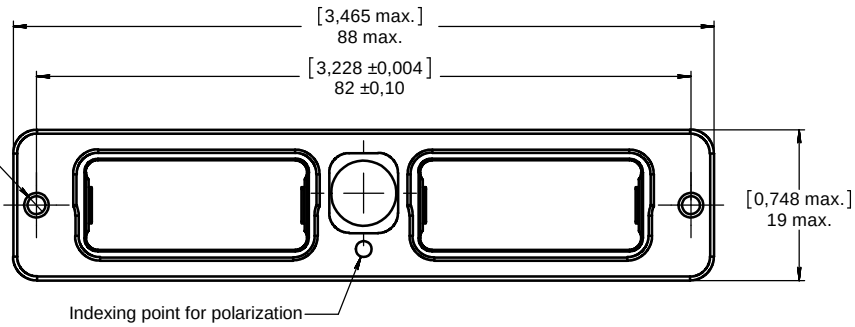


MATERIALS & FINISHES :

- Shell : Aluminium alloy 6061 T651, nickel plated,
- Insert retention clip : Beryllium copper,
- Polarization guide : Stainless steel,


NOTES :

- Connector supplied with
 - . Pin polarization guide for A, B, C, D, E & F polarization P/N : 617 980 037, uninstalled,
 - . Dust cap on each cavity, installed.
- Polarization guide has to be installed with resin (Loctite 272) and torqued at 1.2 Nm onto the shell.
- For side to side mounting, use a 19.50 [.768] min pitch

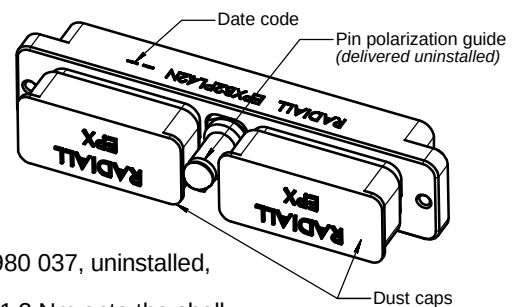


PANEL CUT OUT :

[P] = panel mounting face

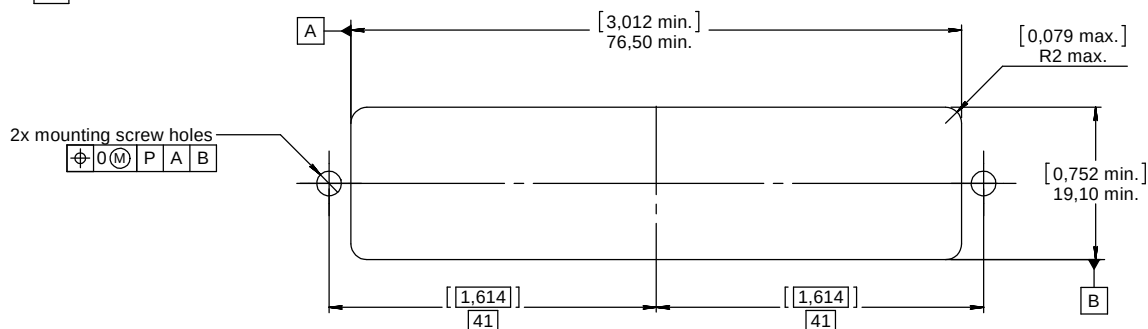

 DIMENSIONS : mm (inch are given for information only)



Estimated weight : 38 Gr

CREATION					
PEN:					
NOM: LEGAVE F.					
DATE: Dec 04, 03					
APPR.: GARCIA L.	Sept 27, 11	guide pin was 617980020 & TDS updated	Pilot N.	Legloahec Y	
	Issue	Revisions	Name	Approved	

EPXB2PL42NEN

RADIALL PROPRIETARY INFORMATION