


Interface Units IEC 807-2 - DIN 41652 (Sub-D Connector)

For D-subminiature plug-in connectors with accessory holes

- With mounting foot for TS 32, TS 35 x 7.5 and TS 35 x 15 rails
- Male and female connectors with screw/locking system UNC 4/40
- Available with screw connection


RD

Male connector with accessory holes[†]

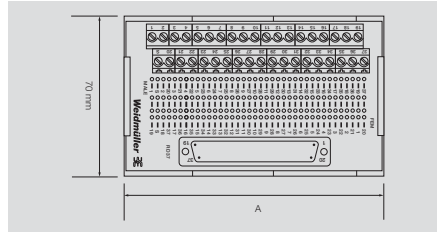

RD

Female connector with accessory holes[†]

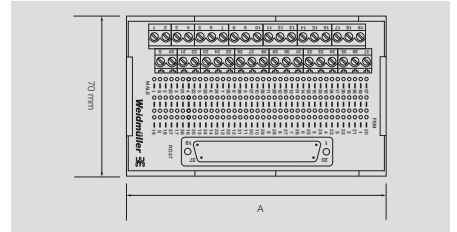

Technical data

Connection data

- Process side
- Type
- Control side
- Type

Rated data

Rated voltage
Rated current per contact
Operating temperature
Storage temperature

Terminal wire size

Insulation stripping length mm (in.)

Dimensions

Overall width mm (in.)

Screw connection
LP2N terminal
Plug connection
Sub-D

150 V
1.5 A
-25°C...+50°C
-40°C...+70°C

AWG 26...12

7 (.28)

See table, dim. A

Screw connection
LP2N terminal
Plug connection
Sub-D

150 V
1.5 A
-25°C...+50°C
-40°C...+70°C

AWG 26...12

7 (.28)

See table, dim. A

Ordering data

dimensions (mm/in.)

Poles	Cable Connector Retainer*	Dim. A
9	Screw	39.88 (1.57)
9	Jackscrew	39.88 (1.57)
15	Screw	55.12 (2.17)
15	Jackscrew	55.12 (2.17)
25	Screw	85.09 (3.35)
25	Jackscrew	85.09 (3.35)
37	Screw	116.84 (4.60)
37	Jackscrew	116.84 (4.60)
50	Screw	149.35 (5.88)
50	Jackscrew	149.35 (5.88)

On TS 35 x 7.5

Type	Order No.
Male w/ accessory holes	
RD-9	912385
RD-9JS	910638
RD-15	912395
RD-15JS	910644
RD-25	912405
RD-25JS	910648
RD-37	913155
RD-37JS	910642
RD-50	911883
RD-50JS	911884

Type	Order No.
Female w/ accessory holes	
RD-9	912380
RD-9JS	910641
RD-15	912390
RD-15JS	912393
RD-25	912400
RD-25JS	910645
RD-37	910075
RD-37JS	910640
RD-50	911885
RD-50JS	911886

Accessories

Mounting rail	
End bracket	for TS 32 for TS 35
Terminal wire marking	

Note :

*Cable connector retainer has either a jackscrew receptacle for a thumb screw or has a mounted screw in the module cable connector.

Type	Order No.
TS 35 x 7.5	0383400000
TS 35 x 15	0498000000
EWK 2	0199360000
EW 35	0383560000
DEK 5	

[†]Designates plug (S male) or socket (B female) connector on the interface module.

Type	Order No.
TS 35 x 7.5	0383400000
TS 35 x 15	0498000000
EWK 2	0199360000
EW 35	0383560000
DEK 5	