

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300680106](#)
Status: **Active**
Overview: [BradPower Cordsets and Receptacles](#)
Description: BradPower D-Size (1 3/8"–M35) 4-Pole Reducing Tee, with 4-Pole BradPower A-Size (7/8"–M22) Drop, Black

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Tees and Splitters
Series [130068](#)
IP Rating IP67
Overview [BradPower Cordsets and Receptacles](#)
Product Name BradPower D-Size
Type Power Tap Tee
UPC 78172546335

Physical

Drop Connector BradPowerA-Size (7/8"–M22)
Drop Gender Female
Keyway Single
Left Trunk Connector BradPower D-Size (1 3/8"–M35)
Left Trunk Gender Female
Leg 1 Length N/A
Leg 2 Length N/A
Material - Cable Jacket N/A
Material - Connector Body PVC
Material - Coupling Nut Anodized Aluminum
Poles 4
Right Trunk Connector BradPower D-Size (1 3/8"–M35)
Right Trunk Gender Male
Temperature Range - Operating -20°C to +90°C

Electrical


Current - Maximum per Contact 15.0A, 32.0A
Voltage - Maximum 600V AC/DC

Material Info

Engineering Number TC40140-200G

Reference - Drawing Numbers

Sales Drawing SD-130068-022

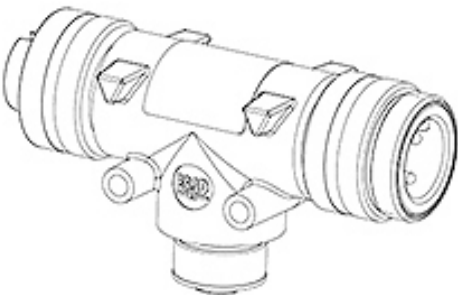

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[130068](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION