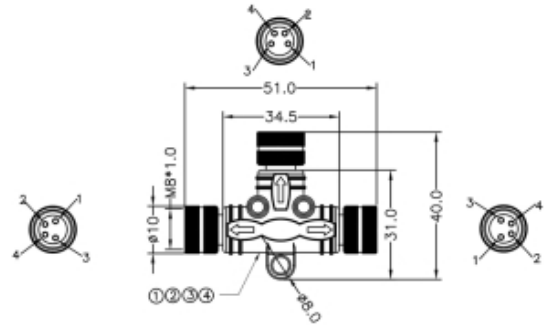


Product Name // PXPPVC08TSFF04AFBBFB [View Product Page](#)

// Product Description:

- | | |
|-------------------------|--------------------------------------|
| Material=Metal | Operating Temperature=-25°C to +85°C |
| Pins=4 | Contact Resistance=3? |
| Max Rating=60Vac | Insulation Resistance=>100M? |
| Ingress Protection=IP67 | Mechanical Cycles=100 (min) |

// General Information:

Product Display Title:	M8 Series T Splitters
Product Family:	Circular Automation Connectors
Product Series:	M8 Series
Body Material:	PVC
Contact Type:	Socket Contact
Number Of Contacts:	4 Contacts

// Product PDF Links



M8 Series automation connectors...

// Product 3D CAD Model Links



PXPPVC08TSFF04AFBBFB3D CAD Model