

*Image for illustrative purpose only*

Summary

[Request a quote](#)[Catalog](#)

| | |
|------------------------------------|------------------------------------|
| Number of contacts Low Voltage | 10 |
| Wire Size/AWG | 28 - 20 |
| Gender | Standard |
| Plug | Plug - Straight |
| Locking system | Push-pull |
| Jacket cable outside diameter [mm] | 9.60 - 10.00 mm |
| Size | 3K |
| Suggested matching part | PHG.3K.310.KLLC10Z |
| Series | K - Outdoor keyed |

Technical details

Electrical Configuration

| | |
|---------------------------------|------------------------------|
| Contact Termination Low voltage | Solder |
| R (max) | 3.6 mOhm |
| Insert configuration value | 3K.310 - 10 Low Voltage |
| Insulator | L: PEEK (UL 94 / V-0/1.5) |
| Rated current | 12 A |
| Vtest (contact-contact) | 1250 V (AC), 1770 V (DC) |
| Vtest (contact-shell) | 900 V (AC), 1270 V (DC) |
| Contact Type | Solder |
| Max. Solid Conductor | 0.5 mm ² (AWG 20) |
| Max. Stranded Conductor | 0.5 mm ² (AWG 20) |
| Bucket Dia. | 1 mm (0.039in) |
| Contact Dia. | 1.3 mm (0.051in) |
| Number of contacts Low Voltage | 10 |
| Wire Size/AWG | 28 - 20 |
| Gender | Standard |

Form & Material

| | |
|------------------------|---|
| Shell style / Model id | FG - Straight plug, cable collet and nut for fitting a bend relief |
| Plug | Straight |
| Housing material | Brass (black chrome) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system | Push-pull |
| Keying | 1 key (alpha=0, plug: male contacts, receptacle: female contacts) |
| Colour | Black |
| Variant | Nut for fitting a bend relief |
| Weight | 65.99 g |

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-310-klac10z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

| | |
|-----------------------------------|---|
| Technical domain | Audio Video, Energy and Industrial, Medical, Test and Measurement |
| Environmental sealing (IP rating) | IP68 |
| Endurance | 5000 mating cycles |
| Temperature range | -55°C / +200°C |
| Climatical Category | 50/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shielding (min) | 95 dB (10 MHz) |
| Shielding (min) | 80 dB (1 GHz) |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |
| Salt Spray Corrosion | >1000 hr |

Cable fixation

| | |
|------------------------------------|-----------------------|
| Cable termination protection | For cable bend relief |
| Fixation type | Cable collet |
| Jacket cable outside diameter [mm] | 9.60 - 10.00 mm |

Drawings

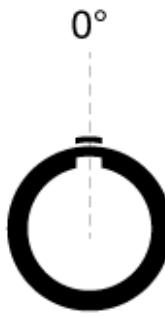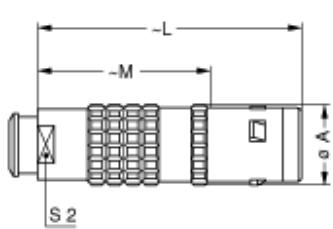

Dimensions

| | M | L | A | S2 |
|-----|----------|----------|----------|-----------|
| mm. | 40 | 60 | 19 | 15 |
| in. | 1.57 | 2.36 | 0.75 | 0.59 |

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-310-klac10z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.