


PXMBNI12RPF04TFLM16001 Datasheet

Product Name // PXMBNI12RPF04TFLM16001

 [View Product Page](#)

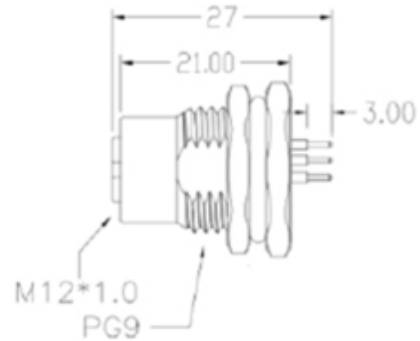

// Product Description:

- | | |
|---|---|
|  Material=Metal |  Operating Temperature= -25°C to +85°C |
|  Pins=4 |  Contact Resistance=5? |
|  Max Rating=60Vac |  Insulation Resistance=>100M? |
|  Ingress Protection=IP67 |  Mechanical Cycles=100 (min) |

// General Information:

Product Display Title:	M12 Front and Rear Panel Mount Flying Lead
Product Family:	Circular Automation Connectors
Product Series:	M12 Series
Body Material:	Brass - Nickel Plated
Contact Type:	Socket Contact
Number Of Contacts:	4 Contacts

// Product PDF Links



M12 Series automation connectors...

// Product 3D CAD Model Links



PXMBNI12RPF04TFLM160013D CAD Model



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)