


EXP-0931/05/P Datasheet

Product Name // Panel Mount Connector EXP-0931 Series
5 Contact Plug

 [View Product Page](#)

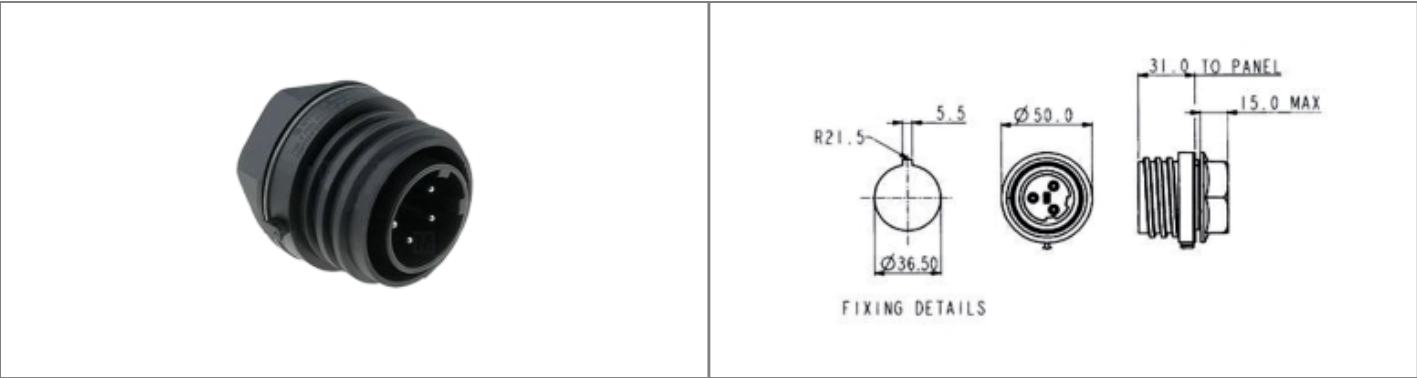

// Product Description:

- Panel Mount Connectors for hazardous areas
 - Water and dustproof to IP68 when mated with compatible connector
 - Positive fast-acting locking ring - can be turned with a gloved hand
 - Plug or Socket
 - 2, 3, 4, 5, 7, 10 Contact with leading Earth on 3, 4, 5, 7 Contact versions, trailing Neutral on 5 Contact version
- Single hole fitting, anti-rotation key
 - Panel thickness 3mm-7mm
 - Supplied with high grade sealing gasket
 - EXP-0992 heavy duty Sealing Cap available separately to maintain IP68 rating of unmated connectors
 - Mate with EXP-0911 and EXP-A911 Series Flex Connectors

// General Information:

Product Display Title:	Panel Mount Connectors for hazardous areas
Product Family:	Circular Power Connectors
Product Series:	EXPlora
Approvals:	UL
Body Material:	Polyester (PET)
Body Material Type:	Plastic Body
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	18A
Diameter Over Coupling Ring Mm:	58mm
Flamability Rating:	UL94V-0
Function:	Front Panel Mount Connector
Ip Rating:	IP68
Max Contact Accomodation Awg:	14AWG
Min Contact Accomodation Awg:	10AWG
Max Contact Accomodation Mm2:	4mm2
Min Contact Accomodation Mm2:	2.5mm2
Max Operating Temperature:	+55°C
Min Operating Temperature:	-20°C
Number Of Contacts:	5 Contacts
Voltage Max:	600V

// Product PDF Links



// Product 3D CAD Model Links

