

# HC-STA-B10-HLWD-1TTM25-EL-AL - Housing



1412638

<https://www.phoenixcontact.com/us/products/1412638>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing B10, with double locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, straight, 1x M25, height: 57 mm, cable gland: none, Standard

## Your advantages

- Good shielding in the event of electromagnetic interference

## Commercial data

|                                      |                     |
|--------------------------------------|---------------------|
| Item number                          | 1412638             |
| Packing unit                         | 1 pc                |
| Minimum order quantity               | 1 pc                |
| Sales key                            | BF56                |
| Product key                          | BF7APB              |
| Catalog page                         | Page 614 (C-2-2019) |
| GTIN                                 | 4055626059648       |
| Weight per piece (including packing) | 173.1 g             |
| Weight per piece (excluding packing) | 167.4 g             |
| Customs tariff number                | 85389099            |
| Country of origin                    | CN                  |

# HC-STA-B10-HLWD-1TTM25-EL-AL - Housing



1412638

<https://www.phoenixcontact.com/us/products/1412638>

## Technical data

### Notes

|         |   |
|---------|---|
| General | for contact inserts HC-B10, BB18, DD42, M, K8/24, HV03                                    |
| General | also available as a powder-coated or color version: 1372772 HC-STA-B10-HLWD-1TTM25-EL/... |


### Product properties

|                              |                            |
|------------------------------|----------------------------|
| Product type                 | Housing with locking latch |
| Housing type                 | Sleeve housing             |
| Application                  | Standard                   |
| Type                         | B10                        |
| No. of cable outlets         | 1                          |
| Type of the screw connection | 1x M25                     |
| Type                         | Low design                 |
| Cable outlet                 | straight                   |
| Pg screw connection          | none                       |

### Data management status

|                  |    |
|------------------|----|
| Article revision | 03 |
|------------------|----|

### Dimensions
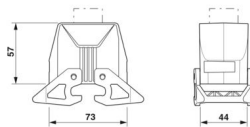
|                     |  |
|---------------------|--|
| Dimensional drawing |  |
| Width               | 44 mm  |
| Height              | 57 mm  |
| Length              | 73 mm  |

### Material specifications

|  |   |
|--|---|
| Flammability rating according to UL 94 | V0 (Interlock)                          |
| Housing material                       | Die-cast aluminum, salt water resistant |
| Housing surface material               | uncoated                                |
| Locking latch material                 | PA                                      |

### Mechanical properties

#### Mechanical data

|                              |        |
|------------------------------|--------|
| Type of the screw connection | 1x M25 |
| Locking type                 | Latch  |

### Environmental and real-life conditions

# HC-STA-B10-HLWD-1TTM25-EL-AL - Housing



1412638

<https://www.phoenixcontact.com/us/products/1412638>

Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Degree of protection            | IP66              |
|                                 | IP67              |
| Enclosure rating (NEMA)         | 4 (UL 50e)        |
|                                 | 4X (UL 50e)       |
|                                 | 12 (UL 50e)       |
| Impact strength                 | IK09              |
| Ambient temperature (operation) | -40 °C ... 125 °C |

# HC-STA-B10-HLWD-1TTM25-EL-AL - Housing


1412638

<https://www.phoenixcontact.com/us/products/1412638>



## Drawings

Dimensional drawing

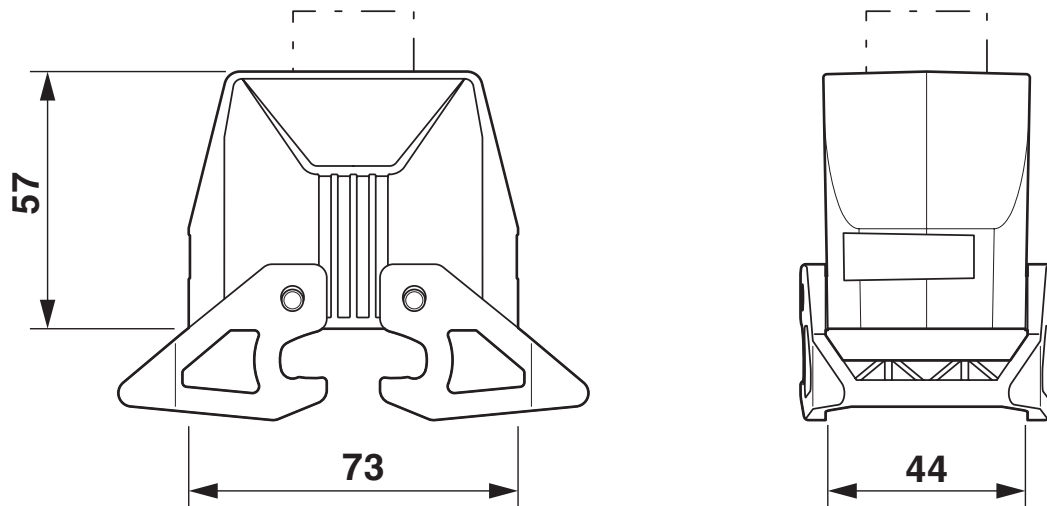

Dimensional drawing

# HC-STA-B10-HLWD-1TTM25-EL-AL - Housing



1412638

<https://www.phoenixcontact.com/us/products/1412638>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1412638>

### DNV

Approval ID: TAE000037S



### EAC

Approval ID: RU C-DE.AI30.B.01102



### EAC

Approval ID: RU C-DE.BL08.B.00511

# HC-STA-B10-HLWD-1TTM25-EL-AL - Housing



1412638

<https://www.phoenixcontact.com/us/products/1412638>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27440202 |
| ECLASS-12.0 | 27440202 |
| ECLASS-13.0 | 27440202 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000437 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# HC-STA-B10-HLWD-1TTM25-EL-AL - Housing



1412638

<https://www.phoenixcontact.com/us/products/1412638>

## Environmental product compliance

|   |  |
|---|--|
| EU RoHS                                 |  |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |  |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|   | No hazardous substances above the limits |
| EU REACH SVHC                           |  |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |

Phoenix Contact 2024 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)