
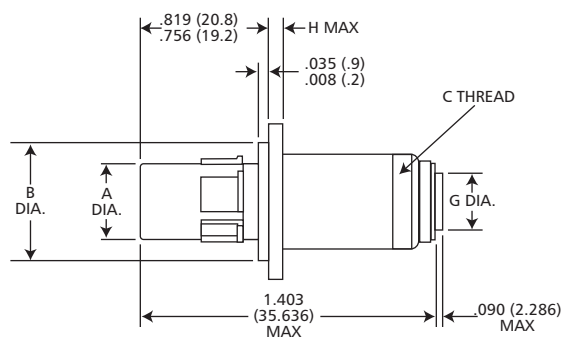


Wall Mounting Receptacle

TKJB0


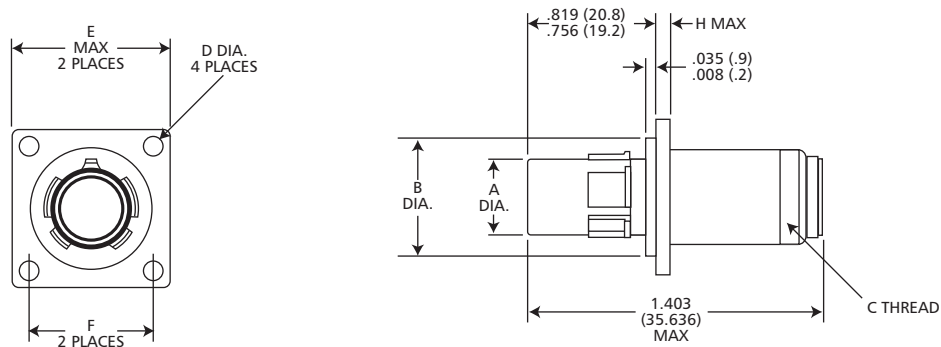


Crimp Piggyback

Shell Size	Shell size Code	A Dia. Max.	B Dia. Max.	C* Thread 1.0-6g 0.100 R	D ± .008 (.20) Dia.	E Dia. Max.	F Basic	G Dia. Max.	H Max
11	B	.509 (12.93)	.793 (20.15)	M15	.130 (3.3)	1.051 (26.7)	.812 (20.62)	.427 (10.85)	.102 (2.590)
13	C	.634 (16.10)	.919 (23.35)	M18	.130 (3.3)	1.146 (29.1)	.906 (23.02)	.541 (13.74)	.102 (2.590)
15	D	.759 (19.28)	1.044 (26.52)	M22	.130 (3.3)	1.240 (31.5)	.969 (24.62)	.666 (16.92)	.102 (2.590)
17	E	.885 (22.48)	1.170 (29.72)	M25	.130 (3.3)	1.335 (33.9)	1.062 (26.98)	.791 (20.09)	.102 (2.590)
19	F	1.009 (25.63)	1.294 (32.87)	M28	.130 (3.3)	1.461 (37.1)	1.156 (29.36)	.880 (22.35)	.102 (2.590)
21	G	1.134 (28.80)	1.419 (36.05)	M31	.130 (3.3)	1.583 (40.2)	1.250 (31.76)	1.005 (25.52)	.134 (3.403)
23	H	1.259 (31.98)	1.544 (39.22)	M34	.150 (3.8)	1.709 (43.4)	1.375 (34.92)	1.130 (28.70)	.134 (3.403)
25	J	1.384 (25.15)	1.669 (42.40)	M37	.150 (3.8)	1.835 (46.6)	1.500 (38.10)	1.255 (31.880)	.134 (3.403)

Jam Nut Receptacle

TKJB7

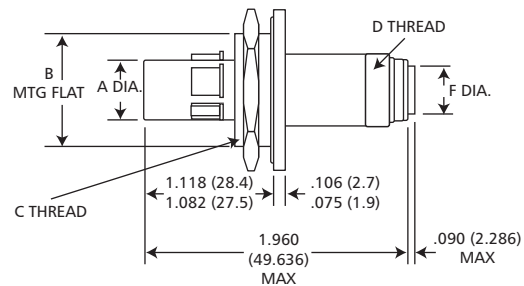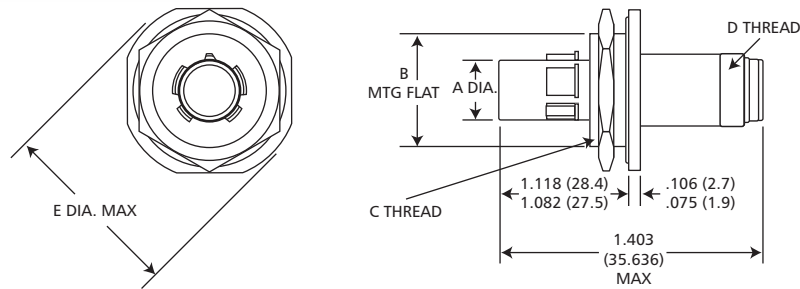

Crimp Piggyback

Shell Size	Shell size Code	A Dia. Max.	B Mtg. Flat (Max.)	C* Thread 1.0-6g 0.100 R	D Thread 1.0-6g 0.100 R	E Dia. Max.	F Dia. Max.
11	B	.509 (12.93)	.942 (23.93)	25	15	1.520 (38.6)	.427 (10.85)
13	C	.634 (16.10)	1.066 (27.08)	28	18	1.642 (41.7)	.541 (13.74)
15	D	.759 (19.28)	1.191 (30.26)	31	22	1.768 (44.9)	.666 (16.92)
17	E	.885 (22.48)	1.321 (33.56)	34	25	1.957 (49.7)	.791 (20.09)
19	F	1.009 (25.63)	1.441 (36.61)	38	28	2.035 (51.7)	.880 (22.35)
21	G	1.134 (28.80)	1.566 (39.78)	41	31	2.157 (54.8)	1.005 (25.52)
23	H	1.259 (31.98)	1.691 (42.96)	44	34	2.283 (58.0)	1.130 (28.70)
25	J	1.384 (25.15)	1.816 (46.13)	47	37	2.409 (61.2)	1.255 (31.880)

Dimensions shown in inch (mm)

Specifications and dimensions subject to change

www.ittcannon.com