


# PXMBNI16FBF03ASCPG9 Datasheet

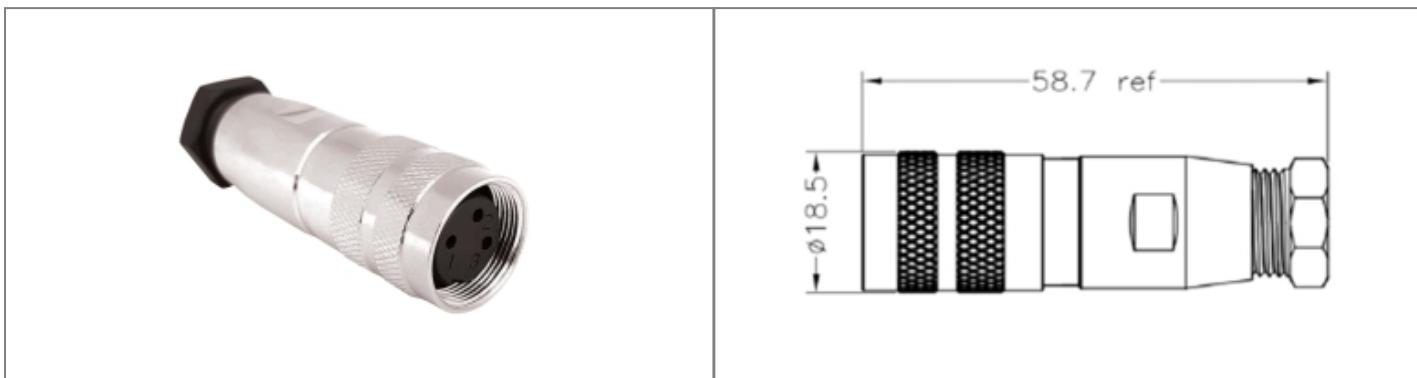

**Product Name // M16 Series A Code Brass Nickel Plated PG9 Flex Body 3 Contact Socket**

[View Product Page](#)


## // Product Description:

- M16 Series Brass Nickel Plated Flex Body Connectors
- Water and dustproof to IP67 when mated with compatible connector
- A Code
- Socket only
- 3, 4, 5, 6, 8, 12 Contact
- Solder Terminals
- Mate with M16 Series Inline Body and Panel Mount Connectors

## // General Information:

Product Display Title:	M16 Series Brass Nickel Plated Flex Body Connectors
Product Family:	Circular Automation Connectors
Product Series:	M16 Series
Change Notes:	PRODUCT-MOQ-ADJUSTMENT
Body Material:	Brass - Nickel Plated
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	7A
Diameter Over Coupling Ring Mm:	18.5mm
Function:	Flex Cable Connector Body
Ip Rating:	IP67
M12 Series Mounting Nut:	PG9
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	3 Contacts
Pin Layout Code:	A Code
Thread Size:	M16 x 0.75
Voltage Max:	250V

## // Product PDF Links

[M16 Series automation connectors...](#)

## // Product 3D CAD Model Links

[PXMBNI16FBF03ASCPG93D CAD Model](#)


Have a question or project enquiry  
you'd like to talk to us about?

[Click Here To Contact Us](#)